

# Idler sprocket for plate chain



## PR882

## For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

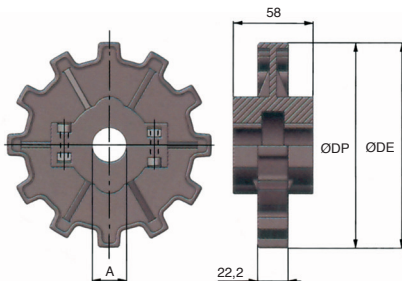


### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm
 
## Our other products



TBV  
Manual lifting tables,  
12kg



VMS  
Stainless steel knurled  
thumb screw, Knurled



PTA80ssEB  
Articulated foot with  
sheet metal base  
Ø80, Articulated foot



GP  
Spring loaded toggle  
latch, With padlock-  
holder



DOMI120  
Domino 120  
adjustable slide, Slide  
DOMILINE 120



SVG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
106,7mm to 121...




PRFSRAD  
Dual lock for  
aluminium profile,  
Quick fitting, self  
locking door du...



E30  
Right angle helical  
reducers, from 1.50 to  
9 Nm



 
HLC28  
Right angle spiro  
bevel gearbox, Up to  
182Nm



TBL  
Mini leadscrew table  
with metric thread,  
1kg



 RPCtcss  
Swivel castor with  
central hole, Stainless  
steel - Polyamide -  
with ...



Q3  
Double row angular  
contact ball bearing,  
Angular contact -  
Steel

## Complementary products



CAP882  
Flexible slat top chain  
acetal, Large range  
882



PT882  
Drive sprocket for slat  
top chain, Range 882