

Manual workbench press

Accessories for PRES-3HR and PRES-4HR presses

PRES

These accessories are only suitable for use with the PRES-3HR and PRES-4HR presses


PRES-PMB: Micrometric adjustment PMB.
Bottom dead centre adjustment system, graduated every 0.02 mm

PRES-TE: Slot nuts for securing tools in the T slot

PRES-ER25: Collet chuck
Collet chuck with ER25 collet for shanks from \varnothing 1.5 to \varnothing 16 mm (Other diameters between 1.5 and 16 mm available on request)



PRES-PMB

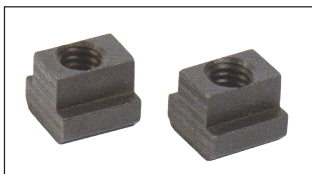

PRES-TE



PRES-ER25

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Type	For shank diameter	Price each
PRES-PMB	Micrometric adjustment (0.02mm)	-	443,90 €
PRES-TE	Set of slot nuts for T profile slots	-	28,91 €
PRES-ER25-1.5	tool holder	1,5	514,70 €
PRES-ER25-2	tool holder	2	514,70 €
PRES-ER25-4	tool holder	4	514,70 €
PRES-ER25-6	tool holder	6	514,70 €
PRES-ER25-8	tool holder	8	514,70 €
PRES-ER25-10	tool holder	10	514,70 €
PRES-ER25-12	tool holder	12	514,70 €
PRES-ER25-14	tool holder	14	514,70 €
PRES-ER25-16	tool holder	16	514,70 €

Dimensions in mm

Our other products



GAL 42

Guide roller for plate chain return, Without ball bearing



SSB

Stainless steel bevel gear, 1:1



HTD8M-BAR

HTD type tooth bar stock, HTD8



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



SLB

Indexing plunger, steel class 5.8



ACLRP

Wheel for aluminium profile, Integrated bearing




SH0

Parallel axis helical gear, Steel 20NCD2



PSG255

 Spur gear - precision range, Stainless steel 303



SBS_M

Single chain supplied by the metre,



DOMI120

Accessories, Plate



SSDB

Stainless steel bevel gear, 2:1



CLB_M

Die cast zinc clamping lever - female, Zamak

Complementary products



PRES3HR

Manual workbench press, Force up to 400kg



PRES4HR

Manual workbench press, Force up to 600kg