

Manual workbench press

Accessories for PRES-3HR and PRES-4HR presses


PRES

These accessories are only suitable for use with the PRES-3HR and PRES-4HR presses


PRES-PMB: Micrometric adjustment PMB.
Bottom dead centre adjustment system, graduated every 0.02 mm

PRES-TE: Slot nuts for securing tools in the T slot

PRES-ER25: Collet chuck
Collet chuck with ER25 collet for shanks from \varnothing 1.5 to \varnothing 16 mm (Other diameters between 1.5 and 16 mm available on request)

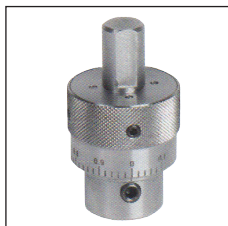

PRES-PMB

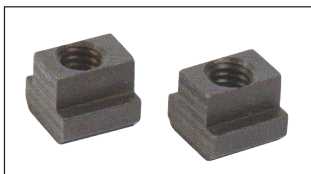

PRES-TE



PRES-ER25

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Type	For shank diameter	Price each
PRES-PMB	Micrometric adjustment (0.02mm)	-	443,90 €
PRES-TE	Set of slot nuts for T profile slots	-	28,91 €
PRES-ER25-1.5	tool holder	1,5	514,70 €
PRES-ER25-2	tool holder	2	514,70 €
PRES-ER25-4	tool holder	4	514,70 €
PRES-ER25-6	tool holder	6	514,70 €
PRES-ER25-8	tool holder	8	514,70 €
PRES-ER25-10	tool holder	10	514,70 €
PRES-ER25-12	tool holder	12	514,70 €
PRES-ER25-14	tool holder	14	514,70 €
PRES-ER25-16	tool holder	16	514,70 €

Dimensions in mm

Our other products



VQT

Quarter-turn clamp lock, Plastic or stainless steel button



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Steel



CLB_M

Die cast zinc clamping lever - female, Zamak



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



 
CHB

Worm and wheel gear reducer, up to 73 Nm



PPOss

Pad eye on mounting plate oval, Stainless steel



TBV

Manual lifting tables, 20kg



AC144

Strike for toggle latch, 22mm



CHA

Heavy duty plastic hinge, opens 180°.



Q6

Deep groove ball bearing, Steel



MACss

Stainless steel carabiner, Stainless



PT880

Drive sprocket for slat top chain, Range 880

Complementary products



PRES3HR

Manual workbench press, Force up to 400kg



PRES4HR

Manual workbench press, Force up to 600kg



PRES2HR

Manual workbench press, Force up to 200kg



PRES5HR

Manual workbench press, Force up to 500kg