

# Manual workbench press

## Accessories for **PRES-3HR** and **PRES-4HR** presses


# PRES

These accessories are only suitable for use with the PRES-3HR and PRES-4HR presses


**PRES-PMB:** Micrometric adjustment PMB.  
Bottom dead centre adjustment system, graduated every 0.02 mm

**PRES-TE:** Slot nuts for securing tools in the T slot

**PRES-ER25:** Collet chuck  
Collet chuck with ER25 collet for shanks from  $\varnothing$  1.5 to  $\varnothing$ 16 mm (Other diameters between 1.5 and 16 mm available on request)

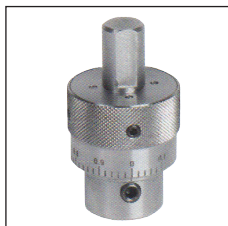

**PRES-PMB**

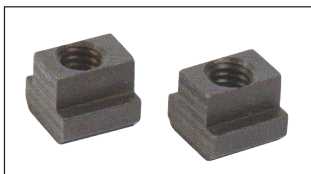

**PRES-TE**



**PRES-ER25**


### DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Type	For shank diameter	Price each
PRES-PMB	Micrometric adjustment (0.02mm)	-	443,90 €
PRES-TE	Set of slot nuts for T profile slots	-	28,91 €
PRES-ER25-1.5	tool holder	1,5	514,70 €
PRES-ER25-2	tool holder	2	514,70 €
PRES-ER25-4	tool holder	4	514,70 €
PRES-ER25-6	tool holder	6	514,70 €
PRES-ER25-8	tool holder	8	514,70 €
PRES-ER25-10	tool holder	10	514,70 €
PRES-ER25-12	tool holder	12	514,70 €
PRES-ER25-14	tool holder	14	514,70 €
PRES-ER25-16	tool holder	16	514,70 €

Dimensions in mm

## Our other products

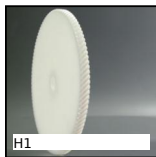

Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)



Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



Stainless steel  
progressive stop,  
stainless steel



Accessories, Plate



Worm and wheel set,  
Bronze



Cap nut Hygienic  
Design®, With collar



 
Stainless steel face  
frame hinge, Surface  
mount



Needle roller universal  
joint - Stainless steel,  
Heavy duty  
DIN808-7...



Wheel - precision  
range, Bronze



Connecting plate for  
RPP type timing belts,  
RPP14



Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -



Knurled knob -  
female, Knurled -  
blind

## Complementary products



Manual workbench  
press, Force up to  
400kg



Manual workbench  
press, Force up to  
600kg