

Manual workbench press



PRES2HR

Force up to 200 kg


- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

Applications

- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

Option

- None available

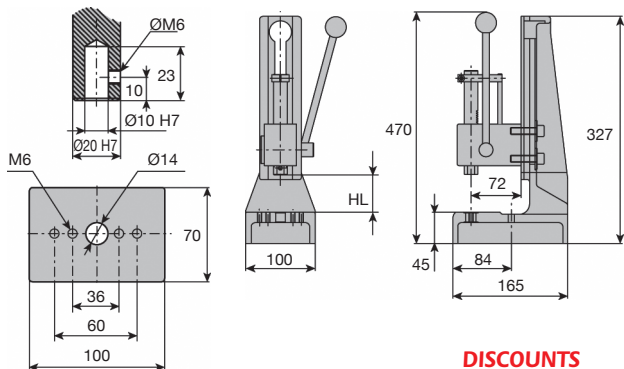

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Force (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Stock*	Price each
PRES-2HR	200	54 - 200	50	72	8	✓	453,57 €

*Subject to available stock - Dimensions in mm

 
HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



INO

Internal gear,
Machined plastic
(delrin)



UTKpwr

Utilitak® V rail, V rail



RPCplss

Swivel castor with
plate, Stainless steel -
Polyamide




SVR20

Screwjack with
travelling nut, with
moving nut



BAN

 Angular clamp,
Standard



BCM_HPBT

Modular cylindrical
brush, PBT polyester
bristles



PCS37SS

Chain sprocket -
Stainless steel, 9.525
(DIN 06B-1)



PSG08

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



MAC

Carabiner DIN5299
steel, Steel



PENV

Recessed handle,
screw fixing



BFM

Flanged bronze nut,
Bronze - 1 thread



GTCSS

Belt tensioner, For use
in hostile
environments

Complementary products



PRES3HR

Manual workbench
press, Force up to
400kg



PRES5HR

Manual workbench
press, Force up to
500kg



CDP

Flanged drill bushing,
Steel



CDPC

Flanged drill bushing,
Steel