



# Manual workbench press

Force up to **400 kg**

**PRES3HR**

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

## Applications


- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

## Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

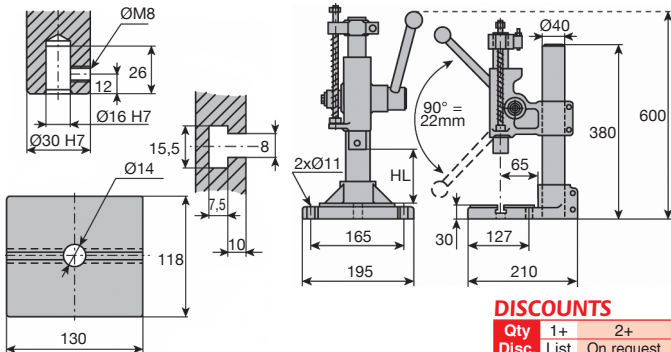

## DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Force (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-3HR	400	35 - 270	80	80	17	Without	858,90 €
PRES-3HR-CPT	400	35 - 270	80	80	17	With	1 167,73 €

\*Subject to available stock - Dimensions in mm

## Our other products



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



BOX-SHNA

Hexagonal nut - DIN934, Box set of steel nuts



GSI

Stainless steel gas spring, Stainless steel



TIFss

Threaded stud - DIN976A, Stainless steel



F7-P-AM

Multifunction display, Magnetic ring



 
J52

Spur gear coaxial gearbox, from 0.27 to 0.90 Nm - Inline




CHAR5050\_Z

Spring hinge, screwed



T2

 T type timing belt, T2.5 Steel cored polyurethane



PF40NM

Worm and wheel gear reducer, up to 18 Nm



LVT

Miniature motorised actuator 2A, 2 amperes



PTA150

Articulated levelling foot, pressed base



BSPT

Single rod clip, Round

## Complementary products



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



CDP

Flanged drill bushing, Steel



CDPC

Flanged drill bushing, Steel