



# Manual workbench press

Force up to **400 kg**

**PRES3HR**

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

## Applications



- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

## Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

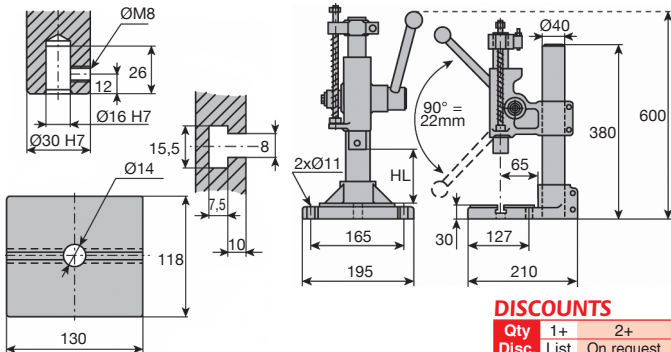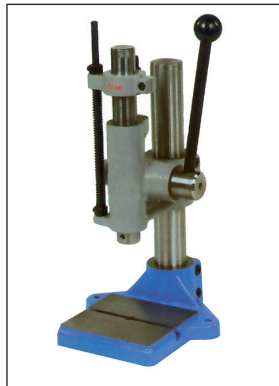


## DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Force (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-3HR	400	35 - 270	80	80	17	Without	858,90 €
PRES-3HR-CPT	400	35 - 270	80	80	17	With	1 167,73 €

\*Subject to available stock - Dimensions in mm

## Our other products

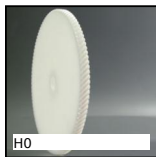

HO

Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)



TBE16

Economic mini-table  
with trapezoidal  
lead screw, 5kg



ADSR

Backlash free  
coupling Gerwah®,  
from 12.5 to 525Nm



DHX

Dowel pin internal  
thread, Extractable  
DIN 7979D



WINGbr

Wing screw, hand  
tightened DIN316,  
Brass DIN 316



BH01

Single housed  
bearing, Bearing fitted  
with adhesive



BABreceptacle

Ball pin socket, Socket



BUH77

Motor-gearbox 12V  
and 24V DC, from 0.1  
to 2 Nm



HTD5M\_09

HTD Heavy duty  
timing pulley, HTD5



PRF\_PF

Anchoring bracket for  
aluminium profile,



DFG

Flat suction cup,  
nitrile



ZDB

Machined plastic  
bevel gear , 2:1

## Complementary products



PRES

Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Micromet...



PRES

Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Set of s...



CDP

Flanged drill bushing,  
Steel



CDPC

Flanged drill bushing,  
Steel