



Manual workbench press

Up to **400 Kg** of pressure

PRES3HR

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

Applications


- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

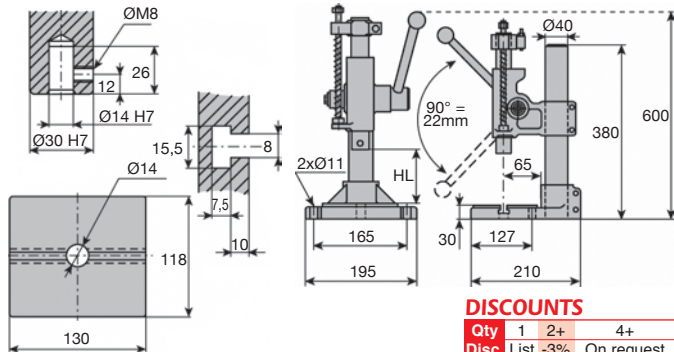

DISCOUNTS

Qty	1	2+	4+
Disc.	List	-3%	On request

Part number	Power (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-3HR	400	35 - 270	80	80	17	Without	792,03 €
PRES-3HR-CPT	400	35 - 270	80	80	17	With	1 076,82 €

*Subject to available stock - Dimensions in mm

Our other products



90° crossed axis helical gear, Machined plastic (delrin)



Support base, Tripod support base



Linear table, For small lengths



Wheel - precision range, Bronze



Cylindrical revolving handle, Folding



Internal gear, Machined plastic (delrin)



Manual bonnet fastener, Black rubber fastener



Internal gear, Steel 20NCD2



Fixable articulated foot - polyamide, Ø 50



Tools Hygienic Usit® and Hygienic Design®.



PERIFLEX elastic coupling, Complete coupling



Indexing plunger, stainless steel

Complementary products



Accessories for PRES-3HR and PRES-4HR presses, Micrometric

adjustment (0.02mm)



Accessories for
PRES-3HR and
PRES-4HR presses,
Set of slot nuts for T

profile slots



CDP

Flanged drill bushing,
Steel



CDPC

Flanged drill bushing,
Steel