

Manual workbench press



PRES4HR

Force up to 600 kg

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

Applications


- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

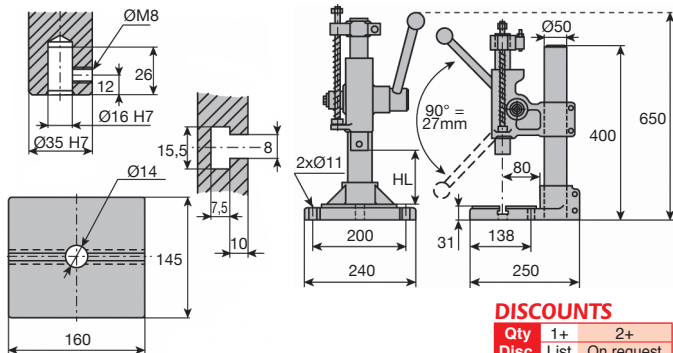

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-4HR	600	46 - 280	100	95	25	Without	955,42 €
PRES-4HR-CPT	600	46 - 280	100	95	25	With	1 264,23 €

Dimensions in mm

Our other products



BPF Lss
Pressed stainless steel flange bearing,
Stainless steel



T5M T10M
T type timing belt per metre, T5 Steel cored polyurethane



WS20
Drylin® W rail, Rail



BAG
Steel Clamping collar,
Steel



RURt
Swivel castor with central hole,
Polyurethane -
Aluminium rim (Free)



R206
Die spring ISO10243,
Extra-heavy



SVT5
Screwjack with travelling screw, with translating screw



KSM
Cylindrical steel nut,
Steel - 1 thread



BTC20_10
End cap for rectangular tube,
Standard



BETASS
Hitch pin, Hitch



GCB880
Curved track for slat top chain, Ranges 880 and 881



H4
Crossed helical gear crossed axis at 90°, Steel 20NCD2

Complementary products



PRES
Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



PRES
Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



CDP
Flanged drill bushing,
Steel



CDPC
Flanged drill bushing,
Steel