

Manual workbench press



PRES4HR

Force up to 600 kg

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

Applications


- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

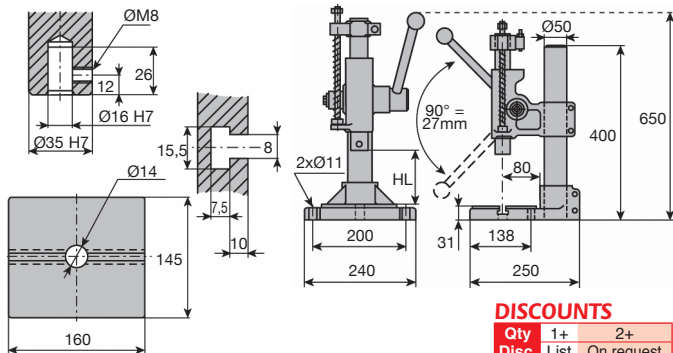

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-4HR	600	46 - 280	100	95	25	Without	955,42 €
PRES-4HR-CPT	600	46 - 280	100	95	25	With	1 264,23 €

Dimensions in mm

 
Our other products



KB_WW
Closed linear
precision bearing,
Economy range



PRES
Manual workbench
press accessory for
PRES-3HR end
PRES-4HR, Set of s...



RPP
Connecting plate for
RPP type timing belts,
RPP14



 
MFB_MHB
Moulded plastic bevel
gear (nylon), 4:1



T5_11
T type timing pulley,
T5 aluminium



MLY
Bow shackle with eye
bolt, Steel



T2
T type timing belt,
T2.5 Steel cored
polyurethane



PPD
Indexing plunger for
sheets, For sheet
metal



TBD
Manual leadscrew
table with opposing
threads, 5kg



DP
Dowel pin, Solid ISO
2338



DOMI30
Connecting kits, XY
linking kit



PARF80
Pressed steel base
rigid foot, Swivelling -
Ø80

Complementary products



PRES
Manual workbench
press accessory for
PRES-3HR end
PRES-4HR, Micromet...



PRES
Manual workbench
press accessory for
PRES-3HR end
PRES-4HR, Set of s...



CDP
Flanged drill bushing,
Steel



CDPC
Flanged drill bushing,
Steel