

# Manual workbench press



## PRES4HR

## Force up to 600 kg

- Rack press
- The force is linear and constant over the full stroke.
- The ram is prevented from turning
- Free height is adjustable
- Stroke adjusts via a screw
- Quick and easy to install

### Applications


- This model is particularly robust and is frequently used for the assembly of parts, simple bending tasks and various fastening operations

### Options

- 5 digit counter with reset button
- Accessories- see accessory page



version with counter

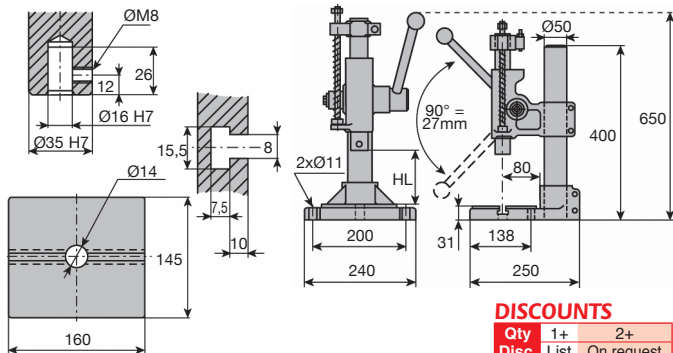

Part number	Power (kg)	Free height HL (mm)	Stroke (mm)	Goose neck depth (mm)	Weight (kg)	Counter	Price each
PRES-4HR	600	46 - 280	100	95	25	Without	955,42 €
PRES-4HR-CPT	600	46 - 280	100	95	25	With	1 264,23 €

Dimensions in mm

## Our other products



PT821

Drive sprocket for slat top chain, Ranges 821 and 805



BLH30

Right angled gearbox, from 1.32 to 4.40 Nm



SERB

Universal latch key, Universal latch key



PR105

Articulated foot Ø103, Ø 103



M1

Worm and wheel set, Non hardened steel



CHAR6035

Spring hinge, screwed/welded



 
LVT

Miniature motorised actuator 2A, 2 amperes



PPOss

Pad eye on mounting plate oval, Stainless steel



T2

T type timing belt, T2.5 Steel cored polyurethane



PRF\_RR

Coupling bar for aluminium profile, Coupling bar



G3

Steel spur gear, Steel 20NCD2



GCH

Linear ball slide Eco Range, economy range

## Complementary products



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



CDP

Flanged drill bushing, Steel



CDPC

Flanged drill bushing, Steel