



# Manual bench press


**500kg** capacity

**PRES5HR**

- **Knee-joint press**
- The maximum power is reached at the end of the stroke
- The travelling nut is prevented from turning
- Adjustable free height
- Screw stroke adjustment
- Quick and easy installation

## Uses

- This model is particularly robust and is normally used for the assembly of parts, simple bending tasks and various fastening operations

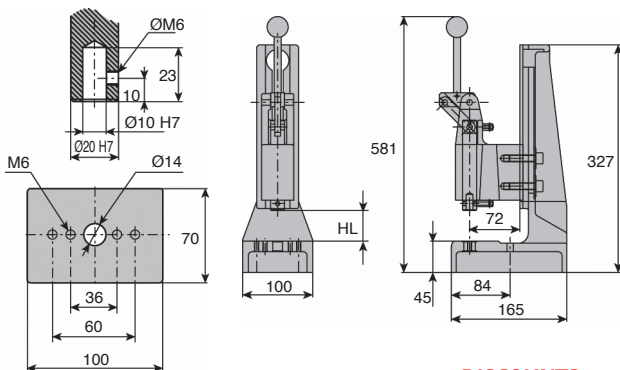

## DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke length (mm)	Goose neck depth (mm)	Weight (kg)	Stock*	Price each
PRES-5HR	500	42 - 185	50	72	9	✓	453,57 €

\*Depending on availability - Dimensions in mm


## Our other products



BAB5303  
303 Stainless steel  
compact ball pin,  
Stainless steel 303



RJA11\_27  
Sealing strip, Not  
clipping

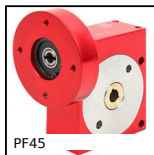

PF45  
Worm and wheel gear  
reducer, up to 40 Nm



TCC  
Rigging screw  
(hook/hook), Steel



GLB  
Small 6 lobe threaded  
handle - female,  
Technopolymer -  
Stainless steel



IN1  
Internal gear, Steel  
20NCD2



GSI  
Stainless steel gas  
spring, Stainless steel



AFSE  
Locking pin with  
interlocking safety  
latch, with  
interlocking safety...



SLB  
Indexing plunger,  
stainless steel



CAP820  
Slim slat top chain  
acetal, Narrow  
straight range 820



TOL  
Swivel head, Long



RJUM05  
Drylin R® linear  
bearing housing,  
Closed - Long

## Complementary products



PRES7HR  
Manual workbench  
press, Force up to  
700kg



PRES3HR  
Manual workbench  
press, Force up to  
400kg



CDP  
Flanged drill bushing,  
Steel



CDPC  
Flanged drill bushing,  
Steel