



Manual bench press


500kg capacity

PRES5HR

- **Knee-joint press**
- The maximum power is reached at the end of the stroke
- The travelling nut is prevented from turning
- Adjustable free height
- Screw stroke adjustment
- Quick and easy installation

Uses

- This model is particularly robust and is normally used for the assembly of parts, simple bending tasks and various fastening operations

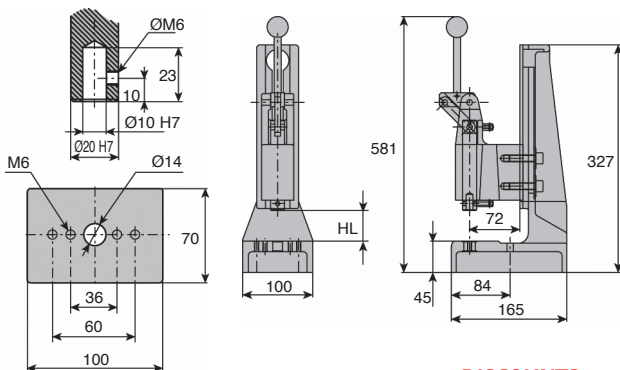

DISCOUNTS

Qty	1+	2+
Disc.	List	On request


Part number	Power (kg)	Free height HL (mm)	Stroke length (mm)	Goose neck depth (mm)	Weight (kg)	Stock*	Price each
PRES-5HR	500	42 - 185	50	72	9	✓	453,57 €

*Depending on availability - Dimensions in mm

Our other products



 PSG08HC
Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



LRH
Bi-directional leadscrew, Bi-directional - 1 thread



EKGS
Backlash free coupling Gerwah®, from 0.5 to 35Nm



HK
Manual locking clamp, Manual locking clamp LWH



TFR
Rigid manual tensioner, Fixed



BSM_LOK
Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



FF10
Offset spur gear reducer, from 0.78 to 3.70 Nm



SH2
Parallel axis helical gear, Steel 20NCD2



PCS25ECO
Chain sprocket - steel, 6.35mm



BAB
Hardened Stainless steel ball pin,



BCM_TP
Modular cylindrical brush, Tampico



Q1
Self-aligning radial ball bearing, Steel

Complementary products



PRES7HR
Manual workbench press, Force up to 700kg



PRES3HR
Manual workbench press, Force up to 400kg



CDP
Flanged drill bushing, Steel



CDPC
Flanged drill bushing, Steel