



Manual bench press


500kg capacity

PRES5HR

- **Knee-joint press**
- The maximum power is reached at the end of the stroke
- The travelling nut is prevented from turning
- Adjustable free height
- Screw stroke adjustment
- Quick and easy installation

Uses

- This model is particularly robust and is normally used for the assembly of parts, simple bending tasks and various fastening operations

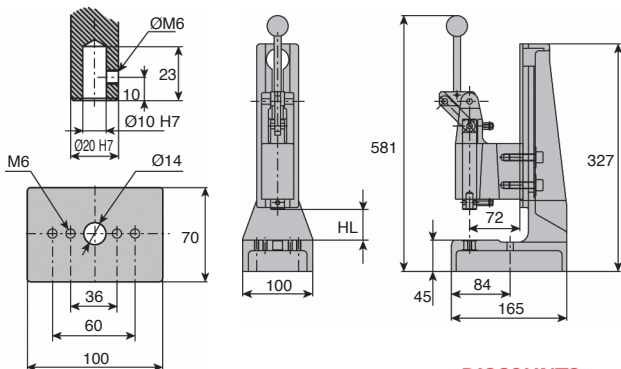

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke length (mm)	Goose neck depth (mm)	Weight (kg)	Stock*	Price each
PRES-5HR	500	42 - 185	50	72	9	✓	453,57 €

*Depending on availability - Dimensions in mm

Our other products



ACL
Connecting/joining,
Variable angle hinge



MSP19
Masterplate®
glueable insert,
Cylindrical with
tapped insert



EPRC
High helix leadscrew,
Cylindrical nut - up to
40mm per rotation



BC3
Panamech, Multi-
Beam, Stainless steel
- with clamping jaw



BMF
Knob for clamping,
Knurled - through
threaded




PRF_CLIP_45
Cable clip, For cable
chute



ALIDRP240
Power supply, 10 A



 PAP
Doorstop and handle,
Ergonomic handle




PO
Housing handle - Multi-
sector, Smooth hole



HG6-ECO
Spur gear, Steel C45



 METC
Bushing, Self-
lubricating sintered
bronze



POA
Magnetic workshop
tool support, Magnetic
bar

Complementary products



PRES7HR
Manual bench press,
Force up to 700kg



PRES3HR
Manual bench press,
Force up to 400kg



CDP
Flanged drill bushing,
Steel



CDPC
Flanged drill bushing,
Steel