



Manual bench press


500kg capacity

PRES5HR

- **Knee-joint press**
- The maximum power is reached at the end of the stroke
- The travelling nut is prevented from turning
- Adjustable free height
- Screw stroke adjustment
- Quick and easy installation

Uses

- This model is particularly robust and is normally used for the assembly of parts, simple bending tasks and various fastening operations

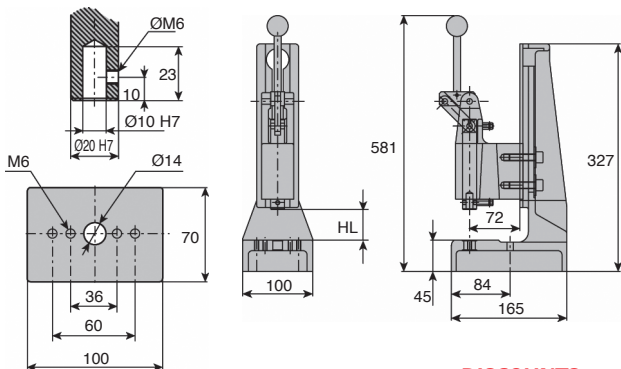

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke length (mm)	Goose neck depth (mm)	Weight (kg)	Stock*	Price each
PRES-5HR	500	42 - 185	50	72	9	✓	453,57 €

*Depending on availability - Dimensions in mm

Our other products



PTAF100-PAMF100
Articulated fixable foot with pressed base Ø100, Ø 100



CDR
Retaining cable for ball pin, Retaining cable



DTR
Chain idler sprocket, Chain idler sprocket - Plastic



CHM30-MOT
Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



CLM
Male clevis end, Steel short



UCP PBT
Stainless/Polymer pillow block bearing, Polymer and stainless steel



PRF_TOOL
Deburring tools for aluminium profile, Deburring tool



PSG05
Spur gear - precision range, Case hardened steel 20NCD2



DBL821
Idler for slat top chain, Range 821



ASM
Cylindrical polymer bush, Food grade



M1
Worm and wheel set, Non hardened steel



BSPT
Single rod clip, Round

Complementary products



PRES7HR
Manual workbench press, Force up to 700kg



PRES3HR
Manual workbench press, Force up to 400kg



CDP
Flanged drill bushing, Steel



CDPC
Flanged drill bushing, Steel