

Manual bench press




PRES7HR

700kg capacity

- **Knee-joint press**
- The maximum power is reached at the end of the stroke
- The travelling nut is prevented from turning
- Adjustable free height
- Screw stroke adjustment
- Quick and easy installation

Uses

- This model is particularly robust and is normally used for the assembly of parts, simple bending tasks and various fastening operations

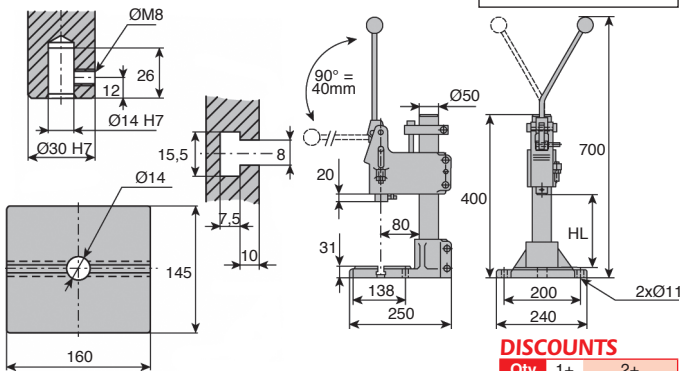

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Power (kg)	Free height HL (mm)	Stroke length (mm)	Goose neck depth (mm)	Weight (kg)	Price each
PRES-7HR	700	35 - 260	40	95	25	955,42 €

Dimensions in mm

Our other products



PPF

Indexing pin, with drilled flange



HLC19

Right angle bevel gearbox, Up to 43Nm



MEB-ALI

Moulded plastic bevel gear (blue nylon), 1:1



PSG1HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



EX

Angle transmission gearbox, E Gearboxes single sided output shaft



BOX-TOR-G

Box set of Nitrile O-rings, 3.00 x 1.50mm to 30.20 x 3.00



ZG4

Spur gear, Machined plastic (delrin)



BEF

Miniature ballscrew, Bearing housing



CNA-CNG

Gas spring, Right angled mounting plate for ball joint



MAC

Carabiner, Steel



DOMI30

DOMILINE - Accessories, Fixing kit



CHA_GC_95S

Stainless steel garnet hinge, To be welded

Complementary products



PRESSHR

Manual bench press, Force up to 500kg



PRES4HR

Manual bench press, Force up to 600kg



CDP

Flanged drill bushing, Steel



CDPC

Flanged drill bushing, Steel