

# Aluminium profile feet support

Very stable

PRFp


- Allows feet or casters to be added to a structure
- Supplied with mounting kit
- Material:  
Aluminium GD, grey painted protective (shore) finish

## Applications


- Mounting of feet or casters

## Assembly

- Mounts directly on the aluminium profile using the screws supplied
- Mount swivelling M10 foot or caster using M10 screw.

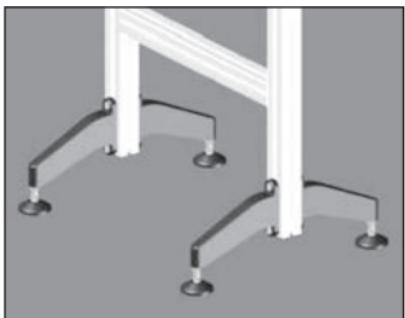

Typical application

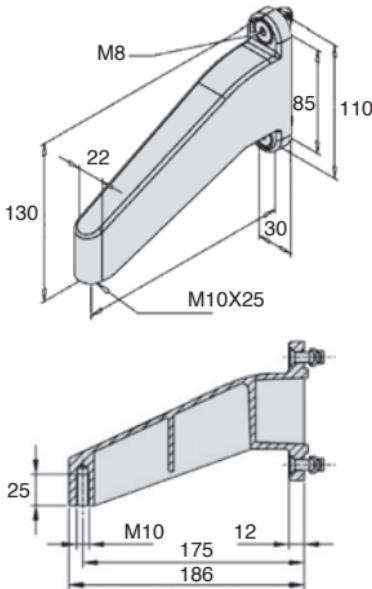

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Price each 1 to 49
PRF-P-175	Foot support	0,368	18,31 €

Dimensions in mm

## Our other products



PTR

Idler chain sprocket,  
For standard  
applications



HSE-HSB

Hexagonal spacer,  
Steel



LRR

Catch-plate for latch,  
Catch-plate



TBD

Manual leadscrew  
table with opposing  
threads, 20kg



LRM2

Cylindrical bronze nut,  
Bronze - 2 threads



RT61

Self-centering locking  
Assembly,  
Medium/low torque



PPF

Indexing plunger with  
flange, with drilled  
flange



NPTF20

Spacer for tube  
carrier, Fixing  
accessory Ø10 to Ø14



GLT2-17

Telescopic drawer  
runners for groove




P30

Worm and wheel gear  
reducer, up to 8.80



HLA24

Right angle spiro  
bevel gearbox, Up to

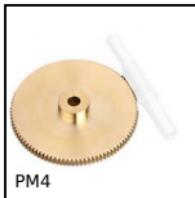

PM4

Worm and wheel set,  
Bronze

## Complementary products



PRF\_BASE

Base plate for  
aluminium profile,  
Base plate