

Lock for aluminium profile

PRF5CL

For sliding doors

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Die-cast aluminium housing with black coating






Advantages

- Easy mounting from the front using CHC M6 screws
- No drilling required


Accessories

- Screws **CHC6-16** and square nut **PRF-ECL-M6**, not supplied

No machining

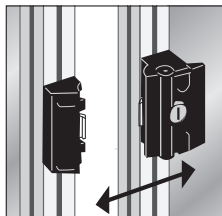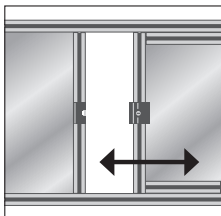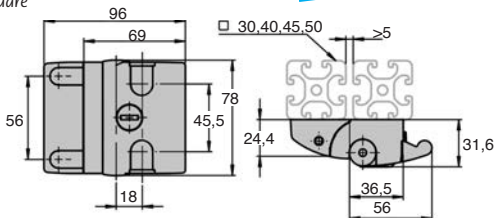

Typical application

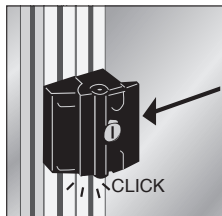

DISCOUNTS

Qty	1+	2+	5+
Disc.	Net	-5%	On request

Part N°	Type	Weight (g)	Price each
PRF-SCL-78-A	With universal key	246	40,22 €
PRF-SCL-78-B	With unique key	246	40,22 €
PRF-SCL-78-C	No key	216	38,42 €

All dimensions in mm

Our other products



RTK

BoWex® curved tooth gear coupling, Nylon and steel



ES

Simple support base (bipod), Plastic



KITbuh

24V DC motorisation kit, Planetary gears



CMA

Eye bolt, Steel



CHAPAM

Weld-on hinge with flat end, Steel



NPTF20

Fixed tube carrier, Fixed Ø10 to Ø14



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80




CPAS

Stay with safety catch, Opens upward



GAL_20

 Conveyor roller for Ø20mm spindle, Self-lubricating polyamide



RPP

Connecting plate for RPP type timing belts, RRP5



GE1006

Elastic ringed latch, Hooks into a slot



SEH

Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...

Complementary products



CHC

Socket headed screw, Steel class 12.19



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF-GPB

Guide for aluminium profile, Rail for 8mm wide slots