




- **Swivel screen support**
- Can be fixed in the slot or on the end of a PRF4545 aluminium profile, or other profiles with 8mm or 10mm grooves
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials:
 - Support plate - PA plastic reinforced glass fibre
 - Hinge - PA plastic reinforced glass fibre
 - Steel screws and bolts

Advantages

- Easy to install on an aluminium profile
- Can be mounted horizontally or vertically for optimised visibility
- Precision finish for maximum strength

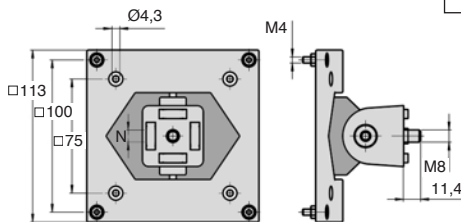

DISCOUNTS

Qty	1+	3+	5+
Disc. Net		-5%	On request

Part N°	Carrying capacity (kg)	N	Weight (g)	Price each 1 to 2
PRF-SCREEN-1	4,9	8 - 10	200	92,79 €

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



F7-SF-5M

Multifunction display,
Right angled
mounting bracket



CHT63

Asynchronous AC
motor 0.12 to 0.22kW,
0.12 to 0.22kW



PSG1HC

Skive hobbled spur
gears - precision
range, Case hardened
steel 20NCD2



HLC24

Right angle spiro
bevel gearbox, Up to
78Nm



RTN

BoWex® curved tooth
gear coupling, Nylon



BTC20_10

End cap for
rectangular tube,
Standard



SHW

Plain washer, Steel



HTD5M-BAR

HTD type tooth bar
stock, HTD5



E60B

Right angle helical
reducers, from 4.50 to



DSF

Slip friction clutch, 4
to 2600 Nm



PTKFss

Cap nut for foot for
the food industry,



GG1

Ground spur gear,
Heat treated steel

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm



PRF4545

Standard stainless
steel profile, 45 x 45
mm



PRF-SCREEN-4

Screen support,
Support with 4 axes of
rotation



PRF-SCREEN-5

Screen support,
Support with 5 axes of
rotation