




- **Swivel screen support**
- Can be fixed in the slot or on the end of a **PRF4545** aluminium profile, or other profiles with 8mm or 10mm grooves
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials:
Support plate - PA plastic reinforced glass fibre
Hinge - PA plastic reinforced glass fibre
Steel screws and bolts

Advantages

- Easy to install on an aluminium profile
- Can be mounted horizontally or vertically for optimised visibility
- Precision finish for maximum strength

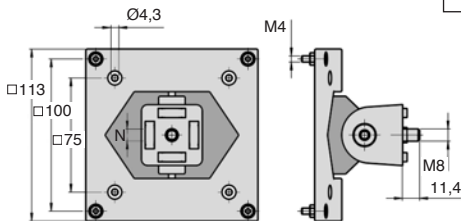

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Carrying capacity (kg)	N	Weight (g)	Price each 1 to 2
PRF-SCREEN-1	4,9	8 - 10	200	92,79 €

Our other products



Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



Worm and wheel gear
reducer, up to 164
Nm



Adjustable suction-
cup support,
Increased grip



Spring loaded plunger
with ball tip, Plastic
body



Indexing plunger with
cam, with cam



 
Detectable plastic
palm grip, by metal
detectors



Hinge and joint, Lift-
off hinge



Miniature motorised
actuator 2A, 2 amperes



Guide for aluminium
profile, Parallel rails



Stainless steel AC
asynchronous motor
0.55 - 0.75kW, 0.55 to



Stainless/Polymer
pillow block bearing,
Cast iron - Split pillow



AT type timing pulley,
Economy range - AT5
aluminium

Complementary products



Standard aluminium
profile, 45 x 45 mm



Standard stainless
steel profile, 45 x 45
mm



Screen support,
Support with 4 axes of
rotation



Screen support,
Support with 5 axes of
rotation