



## Basic support


PRFSCREEN

### - Swivel screen support

- Can be fixed in the slot or on the end of a PRF4545 aluminium profile, or other profiles with 8mm or 10mm grooves
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials:
  - Support plate - PA plastic reinforced glass fibre
  - Hinge - PA plastic reinforced glass fibre
  - Steel screws and bolts

### Advantages

- Easy to install on an aluminium profile
- Can be mounted horizontally or vertically for optimised visibility
- Precision finish for maximum strength

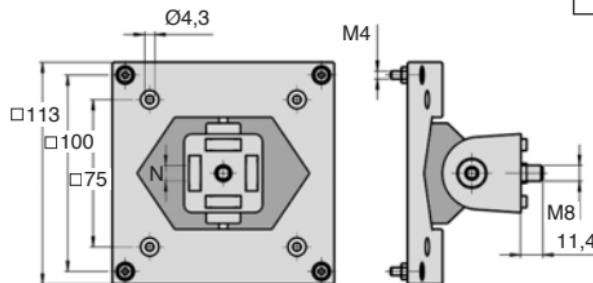

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Carrying capacity (kg)	N	Weight (g)	Price each 1 to 2
PRF-SCREEN-1	4,9	8 - 10	200	92,79 €

Fax

0 825 88 6000

Service 0,15 €/min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

245

## Our other products



M1

Worm and wheel set,  
Hardened steel



CHB

Worm and wheel gear  
reducer, up to 41 Nm



HW-HT

Half-rail guide, Rail



M0

Worm and wheel set,  
Hardened steel



DZYSS

Stainless steel  
cylindrical stop,  
stainless steel



NSR

Adjustable clamp,  
Adjustable



RPP8

RPP heavy duty  
timing belt, RPP8



LVT

Miniature motorised  
actuator 4A, 4 amperes



BPMc

Stainless steel slotted  
spring plunger with  
ceramic ball tip, 303



RFVfp

Stainless steel worm  
and wheel gearbox,  
Mounting bracket



ALIDRP240

24V DC power supply,  
10 A



PRF-GUM

Aluminium profile  
anodising polisher,  
Polishing block

## Complementary products



PRF4545

Standard aluminium  
profile, 45 x 45 mm



PRF4545

Standard stainless  
steel profile, 45 x 45  
mm



PRF-SCREEN-4

Screen support,  
Support with 4 axes of  
rotation



PRF-SCREEN-5

Screen support,  
Support with 5 axes of  
rotation