




- **Swivel screen support**
- Can be fixed in the slot or on the end of a **PRF4545** aluminium profile, or other profiles with 8mm or 10mm grooves
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials:
 - Support plate - PA plastic reinforced glass fibre
 - Hinge - PA plastic reinforced glass fibre
 - Steel screws and bolts

Advantages

- Easy to install on an aluminium profile
- Can be mounted horizontally or vertically for optimised visibility
- Precision finish for maximum strength

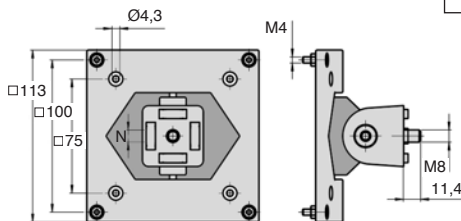

DISCOUNTS

Qty	1+	3+	5+
Disc. Net		-5%	On request

Part N°	Carrying capacity (kg)	N	Weight (g)	Price each 1 to 2
PRF-SCREEN-1	4,9	8 - 10	200	92,79 €

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



NJM

Multiple junction clamp, Multiple



VLBG

Lifting ring, Rotating



GPB

Threaded spherical knob, With brass insert



ZDB

Machined plastic bevel gear, 2:1



SBRtool

Chain tool, Drive chain maintenance tools



ACLLPP

Latch for aluminium profile, Spring operated latch



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter



HTD5M-BAR

HTD type tooth bar stock, HTD5



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



BABS303

303 Stainless steel compact ball pin, Stainless steel 303



PW_PWG15

Worm - precision range, Steel



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free ...

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF4545

Standard stainless steel profile, 45 x 45 mm



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation