

# Screen support for aluminium profile



## PRFSCREEN Support with 4 axes of rotation

- **Screen support on articulated arm**
- Can be fixed in the slot or on the end of a PRF4545 aluminium profile, or on a fixed support
- 360° rotation on the vertical axis
- For screens conforming to VESA75 and VESA100 mounting standards



**Materials :**

- Removable VESA mounting plate - Steel/Plastics
- Screen holder - Cast aluminium, lacquered
- Support plate - Cast aluminium, lacquered
- Adapter - Cast aluminium, lacquered
- Cable cover - Black plastic
- Bearings and washers - Black plastic
- Zinc-plated steel screws



### Advantages

- Easy to install on an aluminium profile
- Adjusts in all directions for optimum visibility
- Careful finishing for maximum strength

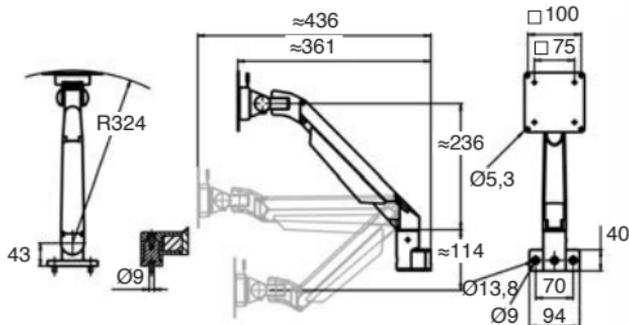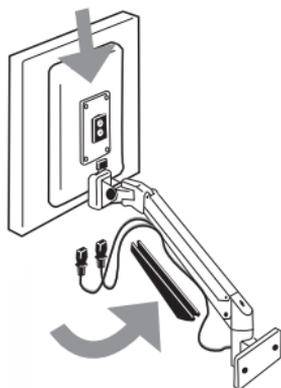

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Carrying capacity (kg)	Weight (g)	Price each 1 to 2
PRF-SCREEN-4	2 - 10	2200	286,03 €

## Our other products



PTA150  
Articulated levelling foot, pressed base Ø150, 40000N



PTA40  
Articulated foot with solid base foot Ø 40, 3000N



EML  
Stainless steel hexagonal headed thumb nut, Lobed handscrew




EPRC  
High helix leadscrew, Cylindrical nut - up to 40mm per rotation



DCA  
Suction cup, 1.5 bellows, nitrile



TRMSS  
Spur round rack, Stainless steel - module 1-5

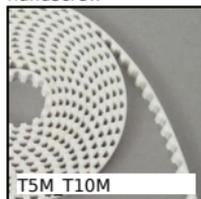


T5M\_T10M  
T type timing belt per metre, T5 Steel cored polyurethane



WSS  
Symmetrical S shaped hook, Steel



KBS\_UU  
Stainless steel closed precision linear bearing, Precision -

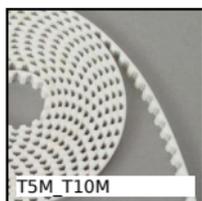

T5M\_T10M  
T type timing belt per metre, T5 Steel cored polyurethane



MDPOT  
Potentiometer,



V3RA\_PT  
3-spoked handwheel with handle, Polyamide

## Complementary products



PRF4545  
Standard aluminium profile, 45 x 45 mm



PRF4545  
Standard stainless steel profile, 45 x 45 mm



PRF-SCREEN-1  
Screen support, Basic support



PRF-SCREEN-5  
Screen support, Support with 5 axes of rotation