

Magnetic lock for aluminium profile

Easily adjustable lock

PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel


Back plate - galvanised steel

Advantages

- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws
- No drilling required

Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided
- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

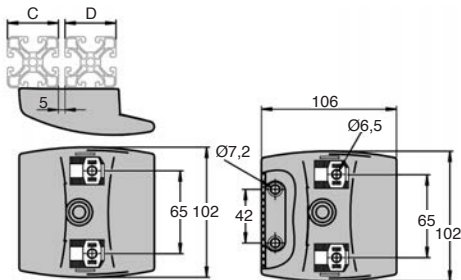

DISCOUNTS

Qty	1+	2+	5+
Disc. Net	-5%	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

241

Our other products

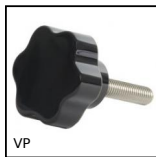

VP

Small 6 lobe threaded handle - male, Duroplast - Steel



RFVcap

Stainless steel protective cover, Open protective cover



SCA

Flat cable clamp, Steel



PSEC

Security pull handle, Thermoplastic



HG6

Steel spur gear, Steel 20NC22



BFA

Shaft locking washer, E clip



CHB

Single output shaft, For CHB gearbox



CHAFR-MINI

Miniature friction hinge, Friction




RBS

Dynamic washer, DIN2093, Steel



PCS62

 Chain sprocket - steel, 15.875 (DIN 10B-1)



TBV

Manual lifting tables, 3kg



VML

Stainless steel hexagonal headed thumb screw, Male

Complementary products



CHC

Socket headed screw, Steel class 12.19



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



FHCSS

Countersunk screw, Stainless steel A2 - DIN 7991



PRF4545

Standard aluminium profile, 45 x 45 mm