

# Magnetic lock for aluminium profile

## Easily adjustable lock

## PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel


Back plate - galvanised steel

### Advantages

- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws
- No drilling required

### Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided
- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

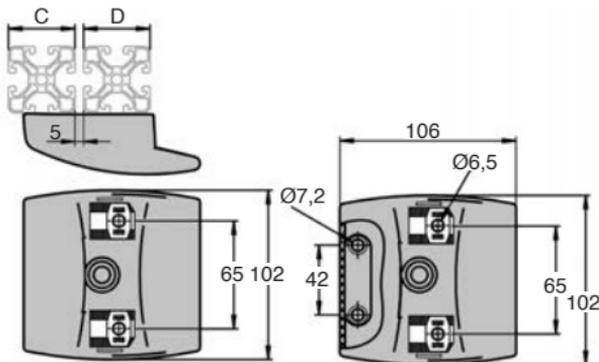

### DISCOUNTS

Qty	1+	2+	5+
Disc. Net	-5%	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**


SUPPLEMENT 2019

241

## Our other products



SRG  
Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm

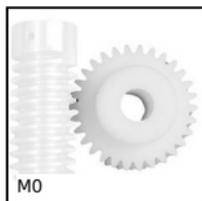

M0  
Worm and wheel set, Machined plastic (delrin)



R203  
Die spring ISO10243, Light



LC  
Friction clutch, 190 to 1800 Nm



GALRUB  
60mm rubber wheel for conveyor belt, Rubber



PF60  
Worm and wheel gear reducer, up to 118 Nm



SLB  
Indexing plunger, stainless steel



FBL6000\_K1  
Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide 6 -...



LVT  
Miniature motorised actuator 2A, 2 amperes



CTZYSS  
Stainless steel diablo shaped elasto, up to 118 Nm



P15  
Worm and wheel gear reducer, up to 3,75 Nm



PSP  
Support profile, Panel support

## Complementary products



CHC  
Socket headed screw, Steel class 12.19



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab



FHCSS  
Countersunk screw, Stainless steel A2 - DIN 7991



PRF4545  
Standard aluminium profile, 45 x 45 mm