

Magnetic lock for aluminium profile

Easily adjustable lock

PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel


Back plate - galvanised steel

Advantages

- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws
- No drilling required

Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided
- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

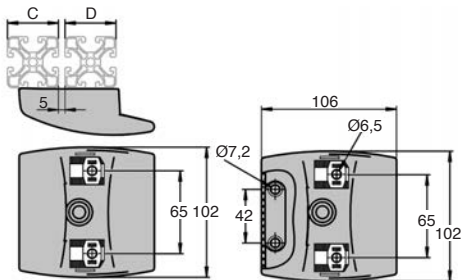

DISCOUNTS

Qty	1+	2+	5+
Disc. Net	-5%	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

241

Our other products

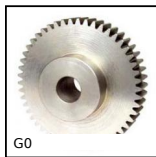

G0

Steel spur gear, Steel
20NCD2



ADL_M

Male eye bolt
conforms to DIN580,
Stainless steel




AT10-25ECO

AT type timing pulley,
Economy range -
AT10 aluminium



PAL

 Self locking counter
nut, For axial locking



CT

Telescopic universal
joint, Normal duty




CHAPAM

Weld-on hinge with
flat end, Steel



NT62

Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line

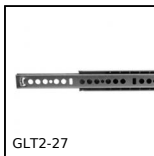

GLT2-27

Telescopic drawer
runners for groove
mounting, Partial
extension



HTD14M_85

HTD Heavy duty
timing pulley, HTD14
Steel




CLLCLLP

Clevis components,
long version, Steel -
long range



T5M_T10M

T type timing belt per
metre, T10 Steel
cored polyurethane

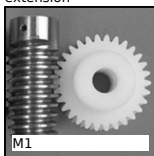

M1

Worm and wheel set,
Machined plastic
(delrin)

Complementary products



CHC

Socket headed screw,
Steel class 12.19



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



FHCSS

Countersunk screw,
Stainless steel A2 -
DIN 7991



PRF4545

Standard aluminium
profile, 45 x 45 mm