

Magnetic lock for aluminium profile

Easily adjustable lock

PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel

Back plate - galvanised steel

Advantages


- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws

- No drilling required

Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided

- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

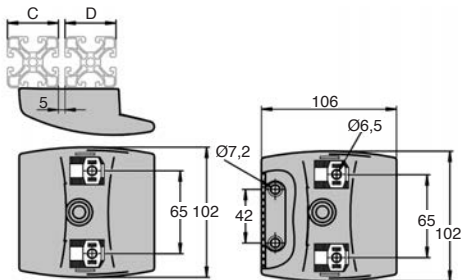

DISCOUNTS

Qty	1+	2+	5+
Disc.	Net	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

241

Our other products



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...



MPB

Hexagonal spacer, Brass



T10courroie

T type timing belt, T10 Steel cored polyurethane



TBE12

Economic mini-table with trapezoidal lead screw, 2kg



BFDdII

Locking pin for bushes, Nickel-plated steel



VDS

Sliding lock adjustment system, Sliding lock for oblong hole



MFBS

Stainless steel flexible bellows coupling, Stainless steel - with se...



BTC_M

End cap with threaded insert for square tube, With threaded insert



CHAR5050_Z

Spring hinge, screwed



BC2

Panamech, Multi-Beam, Aluminium -



SH1

Parallel axis helical gear, Machined plastic



BPTR

End cap for round tube, Standard

Complementary products



CHC

Socket headed screw, Steel class 12.19



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



FHCS

Countersunk screw, Stainless steel A2 - DIN 7991



PRF4545

Standard aluminium profile, 45 x 45 mm