

# Magnetic lock for aluminium profile

## Easily adjustable lock

## PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel


Back plate - galvanised steel

### Advantages

- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws
- No drilling required

### Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided
- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

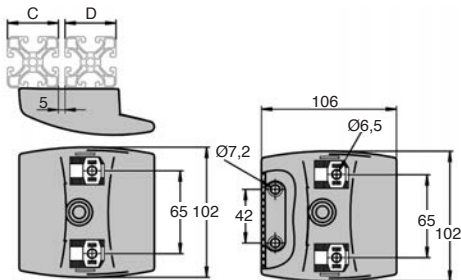

### DISCOUNTS

Qty	1+	2+	5+
Disc. Net	-5%	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

241

## Our other products



BPM\_LOK  
Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Steel




SRG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
78mm to 90mm



BAG-MISS  
Split shaft collar with  
clamp lever, Stainless  
steel



MSP3815  
Masterplate®  
glueable insert  
rectangular,  
rectangular with

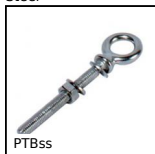

PTBss  
Threaded eye hook  
stainless steel,  
Stainless steel



CHAC4040SS  
Square hinge with  
riveted pin, drilled,  
Square with riveted  
pin, dri...



PLA  
Flat magnet, Flat  
magnet with threaded  
hole



CHTRP  
Single and dual  
output gearboxes, Up  
to 28,8 Nm



CLB\_M  
Die cast zinc clamping  
lever - female, Zamak



CHMR75  
Worm and wheel gear  
reducer, up to 298  
Nm



GPB  
Threaded spherical  
knob, With brass  
insert



HTD8M\_20  
HTD Heavy duty  
timing pulley, HTD8  
Steel

## Complementary products



CHC  
Socket headed screw,  
Steel class 12.19



PRF\_ECL  
Nut for aluminium  
profile, Steel square  
nut with tab



FHCSS  
Countersunk screw,  
Stainless steel A2 -  
DIN 7991



PRF4545  
Standard aluminium  
profile, 45 x 45 mm