

# Lock for aluminium profile

 


PRFSRA **Quick fitting,** self locking door lock

- Door or trap lock for structures assembled from PRF4545 aluminium profiles

- Material:

Die cast aluminium housing with black finish



No machining required





## Advantages

- Easy to mount from the front using M6 CHC screws
- No drilling required

## Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

**NEW!**

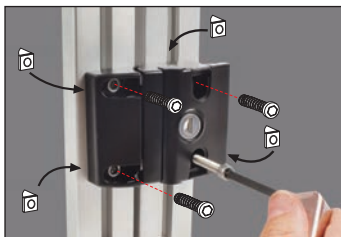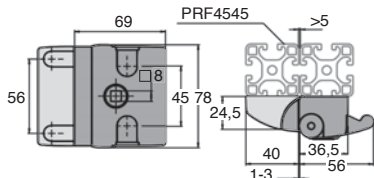

Front mounting


## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Type	Weight (g)	Price each
PRF-SRA-78-A	With universal key	235,5	34,96 €
PRF-SRA-78-B	With individual key	235,5	34,96 €
PRF-SRA-78-C	No key	204,0	33,55 €

Dimensions in mm

## Our other products

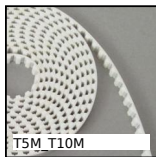

T5M T10M  
T type timing belt per metre, T5 Steel cored polyurethane



SSB  
Stainless steel bevel gear, 1:1



CAP821  
Slat top chain acetal, Large range 821



MHSC  
Single-disc flexible coupling, Single disk



E20  
Right angle helical reducers, from 0.60 to 3.84 Nm




M0  
Worm and wheel set, Bronze



EHD12  
Internal epicyclic servo reducers, from 60 to 140 Nm



 BPM\_LOK  
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



IN2  
Internal gear, Machined plastic (delrin)



EHD06  
Internal epicyclic servo reducers, from 8 to 19 Nm



ESCON  
Speed controller 5A accessories, USB cable for PC link



SNG  
Stainless/Polymer pillow block bearing, Cast iron - Split pillow

## Complementary products



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab



PRF4545  
Standard aluminium profile, 45 x 45 mm



PRF-SMA  
Closing system for aluminium profile, Easily adjustable lock



PRF-SCL  
Lock for aluminium profile, Lock for sliding doors