

Base plate

Stock

PRFBASE *MiniTec* For anchoring to a floor

- For anchoring vertical profiles to a floor
- Grey end caps supplied
- Fixing kit not supplied

Assembly


- Connected using 1 or 2 PR-FIX-UNI universal fasteners on the end of the profile
- When anchoring to a floor, 2 anchoring systems are required




PRF45-BASE




PRF4590-BASE

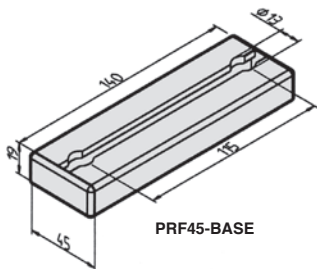

PRF45-BASE

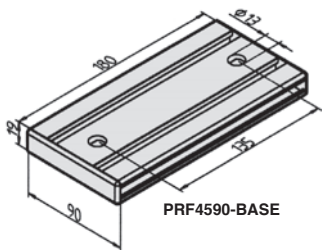

PRF4590-BASE

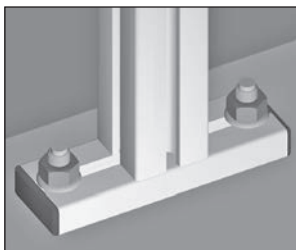

Typical application

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF45-BASE	PRF45	0,125	✓	15,50 €
PRF4590-BASE	PRF4590	0,329	✓	13,35 €

*Depending on availability - Dimensions in mm

Our other products



CHALss

Piano hinge, Stainless steel



BHC

Socket head button screw, Stainless steel A2



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



PR820

Idler sprocket for slat top chain, Rangs 820 and 815



CAP882

Flexible slat top chain acetal, Large range 882




EHD08-3

Internal epicyclic servo reducers, from 20 to 50 Nm



DTR

Chain idler sprocket, Chain idler sprocket - Plastic

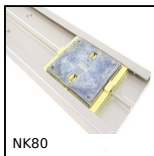

NK80

Drylin®N miniature guiding system, Width 80mm



SME

Male rod ends, stainless steel / PTFE



CHB

Reaction arm, CHB gear reducers reaction arm



RAGb

Cylindrical brush track, For gentle conveying and



RFVbr

Stainless steel reaction arm, Reaction arm

Complementary products



PRF4590

Standard aluminium profile, 45 x 90 mm



PRF_FIX_UNI

Universal fastener for aluminium profile, Universal