

Base plate

Stock

PRFBASE *MiniTec* For anchoring to a floor

- For anchoring vertical profiles to a floor
- Grey end caps supplied
- Fixing kit not supplied

Assembly


- Connected using 1 or 2 PR-FIX-UNI universal fasteners on the end of the profile
- When anchoring to a floor, 2 anchoring systems are required




PRF45-BASE




PRF4590-BASE

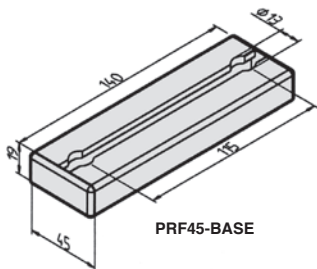

PRF45-BASE

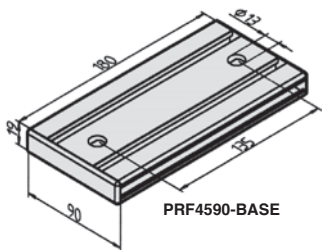

PRF4590-BASE

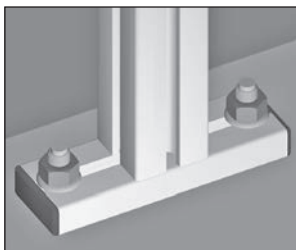

Typical application


DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF45-BASE	PRF45	0,125	✓	15,50 €
PRF4590-BASE	PRF4590	0,329	✓	13,35 €

*Depending on availability - Dimensions in mm

Our other products

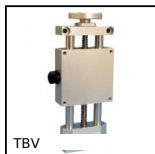

TBV

Manual lifting tables,
3kg




SBS_L

Chain link, Stainless
steel



CHM75

Worm and wheel gear
reducer, up to 298
Nm

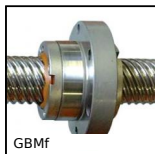


GBMf

Flanged leadscrew
nut, Flanged nut -
Multiple starts



PW_PWG15

Worm - precision
range, Stainless steel

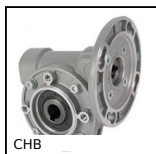


CHB

Worm and wheel gear
reducer, up to 73 Nm



MRA

Quick link, Steel

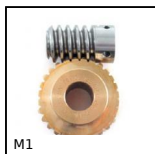

M1

Worm and wheel set,
Bronze



PR882

Idler sprocket for slat
top chain, Range 882



LRR-53

Spring loaded latch,
Spring return latch -
steel



SF_ZZ

Deep groove ball
bearing, Stainless
steel



BTC_M

End cap with threaded
insert for square tube,
With threaded insert

Complementary products



PRF4590

Standard aluminium
profile, 45 x 90 mm



PRF_FIX_UNI

Universal fastener for
aluminium profile,
Universal