


- Base plate for attaching foot or lifting ring
- Fixing kit supplied
- Feet/lifting ring not supplied
- Material: grey powder covered steel

Assembly


- Fits in slot on profile

Accessories

- PR/PRS/PAT/PAM ranges of feet

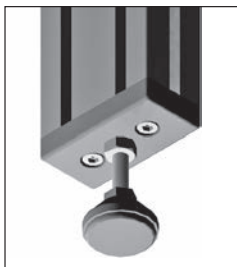

Typical application

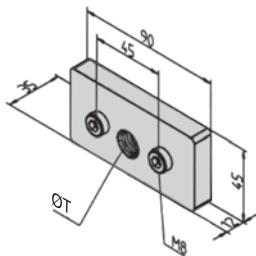

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	ØT Thread	For profile	Thickness (mm)	Weight (kg)	Stock*	Price each 1 to 49
PRF4590-BM10	M10	PRF4590	15	0,164	-	10,45 €
PRF4590-BM12	M12	PRF4590	15	0,162	✓	10,45 €
PRF4590-BM16	M16	PRF4590	15	0,160	✓	10,45 €
PRF4590-BM20	M20	PRF4590	15	0,156	-	10,45 €

*Depending on availability - Dimensions in mm

Our other products



SPIT

Floor mounting levelling plate, With anchoring point



SSB

Stainless steel bevel gear, 1:1



PT820

Drive sprocket for slat top chain, Ranges 820 and 815



ZG0

Plastic spur gear, Machined plastic (delrin)



LRX

Linear roller slide, Rail - from 9410 N to 101000 N



BPVMss

Stainless steel miniature ball transfer unit, Miniature to screw



PRF JL6

Lip seal for panel, Door seal - Ø 6mm



RFK58B

Hypoid gearbox - Stainless steel, up to 500 Nm



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm




RAM30

Manual bevel gearbox, Bevel



CHAK

 Hi-Klik™ TM indent hinge, Hi-Klik™ - Detent hinge



H3

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)

Complementary products



PRF4590

Standard aluminium profile, 45 x 90 mm



PR40

Articulated foot Ø40, Ø 40