


- Base plate for attaching foot or lifting ring
- Fixing kit supplied
- Feet/lifting ring not supplied
- Material: grey powder covered steel

Assembly


- Fits in slot on profile

Accessories

- PR/PRS/PAT/PAM ranges of feet

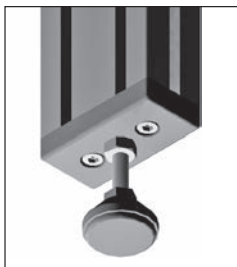

Typical application

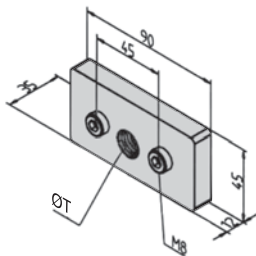

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	ØT Thread	For profile	Thickness (mm)	Weight (kg)	Stock*	Price each 1 to 49
PRF4590-BM10	M10	PRF4590	15	0,164	-	10,45 €
PRF4590-BM12	M12	PRF4590	15	0,162	✓	10,45 €
PRF4590-BM16	M16	PRF4590	15	0,160	✓	10,45 €
PRF4590-BM20	M20	PRF4590	15	0,156	-	10,45 €

*Depending on availability - Dimensions in mm

Our other products



WJRM
Drylin® W hybrid bearing block, Hybrid bearings



 
MFB_MHB
Moulded plastic bevel gear (nylon), 4:1



V3RA_PT
3-spoked handwheel with handle, Polyamide



BEAS
Star shaped anti-static handle, Star, anti-static



SHWbr
Washer - DIN125, Brass



P-FLEX Coupling, Set screw



METC
Flanged sintered bronze bush, Self-lubricating sintered bronze



TAC
Rigging screw (hook/eye), Steel



PLB
Cylindrical spacer, Brass



IBjss
Ball and socket joint, Stainless steel



ACLEPP
Right angled bracket for aluminium profile, 4 holes



FDSQ
Flexible drive shaft, Masterflex® Steel, with PVC casing

Complementary products



PRF4590
Standard aluminium profile, 45 x 90 mm



PR40
Articulated foot Ø40, Ø 40