





## For mounting additional panels

# MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

### Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

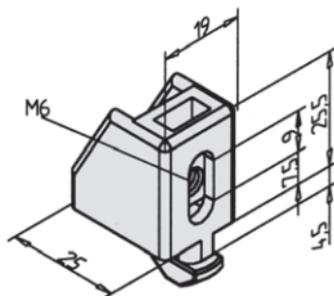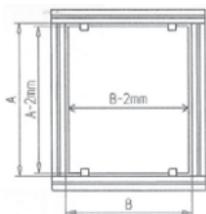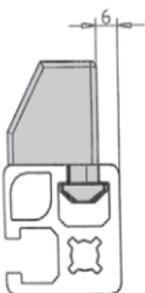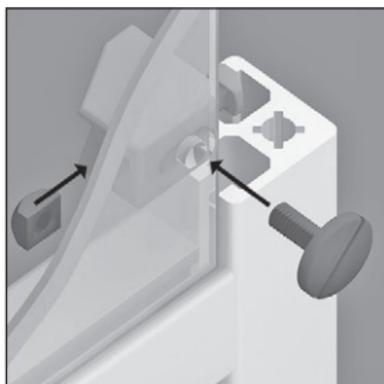

### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

\*Depending on availability - Dimensions in mm

## Our other products



CHAupa

Front hinge, 270°



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



RTE

Rotex®, jaw coupling, steel



GP

Spring loaded toggle latch, Standard



RAM30

Manual bevel gearbox, Bevel



ESCON

Speed controller 5A accessories, Kit of 4 cables for DC motor



OP3\_14\_06

Reducing sleeve for OP indicators, Reduction socket



S2B

Short linear bearing housing, Closed - Slim



PTKFss

Cap nut for foot for the food industry, Stainless steel blind



RDE-N

Sealing washer Hygienic Usit®, Stainless steel - Black



RBN

Wheel, Rubber tyre - Polypropylene rim



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm