



 

For mounting additional panels

MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

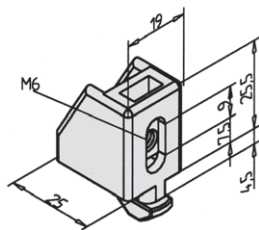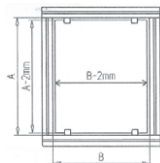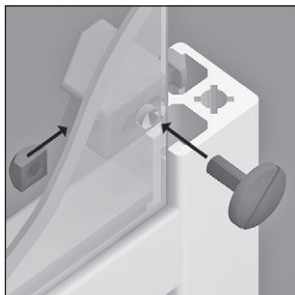

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	On request

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

*Depending on availability - Dimensions in mm

Our other products



GPB55
Threaded spherical knob, Stainless steel 304



LF
Precision locknut, Precision locknut



DOMI80
Accessories, Clamping lever



 
HRV
V-rail guidance Simple Select® system, Rail with carriage



TBD
Manual leadscrew table with opposing threads, 5kg



MEB
Moulded plastic bevel gear (nylon), 1:1




PTR
Idle chain sprocket, For standard applications



PFM
Fixed levelling foot, Flanged plate



 FF10
Offset spur gear reducer, from 0.78 to 5.5kg



QNUP
Single row cylindrical roller bearing, 1 fixed



PTA80ssEB
Articulated foot with sheet metal base



TCL-ECL
Support rod for heavy loads, Support spindle

Complementary products



PRF4545
Standard aluminium profile, 45 x 45 mm