




For mounting additional panels

MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

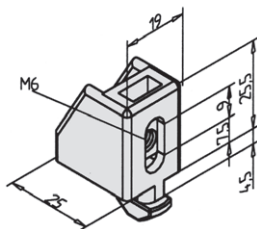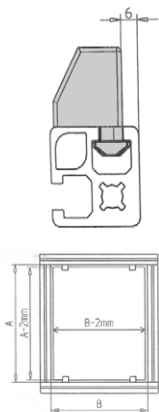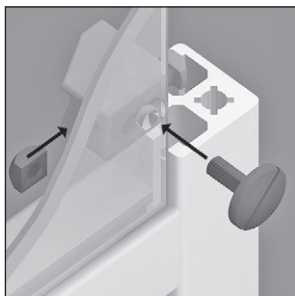

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each
PRF-BV	all types from PRF32	0,01	✓	1 to 49 3,09 €

*Depending on availability - Dimensions in mm

Our other products



Plastic sprocket,
12.7mm (DIN 08B-1)



Right angle helical
reducers, from 2.30 to
20 Nm




Supported shaft for
linear guide, Steel
shaft / Aluminium
support



Combined bearing
without inner ring,
Needle and ball
bearings



Stainless steel elastomount,
stainless steel

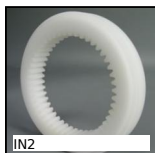

Internal gear,
Machined plastic
(delrin)




Asynchronous AC
motor, 0.09kW



Worm and wheel set,
Machined plastic
(delrin)



Right angled gearbox,
from 0.66 to 1.77 Nm

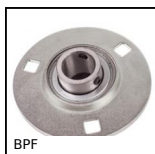

Sheet steel flanged
bearing for light
loads, Sheet steel



Asynchronous AC
Motor, 0.18 to 0.55kW



Internal epicyclic
servo reducers, from
8 to 19 Nm

Complementary products



Standard aluminium
profile, 45 x 45 mm