



 

## For mounting additional panels

# MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

### Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

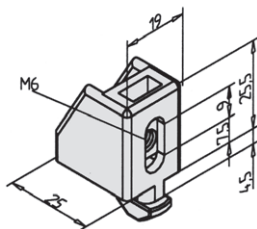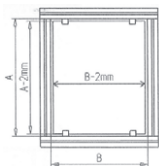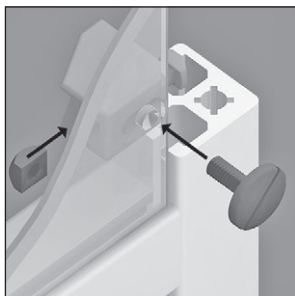

### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

\*Depending on availability - Dimensions in mm

## Our other products



CQA20

Adjustment slide-system miniature, 20



EKG5

Backlash free coupling Gerwah®, from 0.5 to 35Nm



CLB\_M

Die cast zinc clamping lever - female, Zamak



RPP

Connecting plate for RPP type timing belts, RRP5



YG0

HEAVY DUTY spur gear, Steel 35NCD6



PRF\_BASE

Base plate for aluminium profile, Base plate



M2

Worm and wheel set, Unhardened steel



BAGtr

Lead screw clamping collar, Aluminium



PLN

Cylindrical spacer, Thermoplastic



CHM90

Worm and wheel gear reducer, up to 540 Nm



PCS8ECO

Chain sprocket - steel, 8mm (DIN 05B-1)



AT10-50ECO

AT type timing pulley, Economy range - AT10 aluminium

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm