

# Cable-carrier chain for aluminium profile

PRFCH **MiniTec** For profile PRF4545-G-3



- Supplied in metre lengths, this chain simply clips together
- 2 part fixing link required
- Material: black plastic

## Uses

- For supporting and guiding cables/hoses on moveable structures such as trolleys


## Assembly

- PRF4545-ACH links permit multiple chains to be joined to obtain the total length required
- Clip chains together to get the length desired

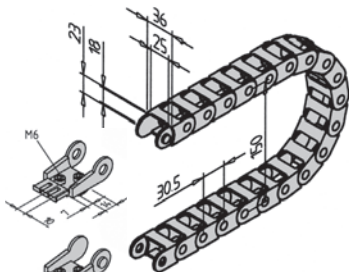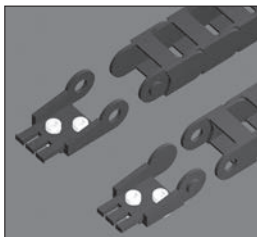

PRF4545-CH

PRF4545-ACH

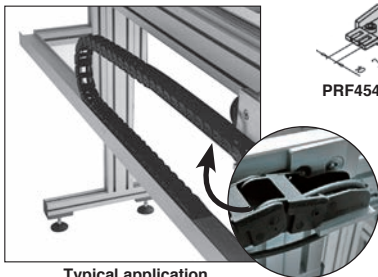

Typical application


## DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request


Part number	Type	Length (mm)	Weight (kg)	Price each 1 to 4
PRF4545-CH	Cable-carrier chain	1000	0,341	108,08 €
PRF4545-ACH	Link	-	0,058	24,01 €

Dimensions in mm

## Our other products

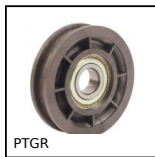

PTGR  
Tensioner pulley, For round belts

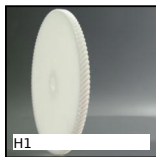

H1  
Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)



CHAsb89  
Hinge without pin,  
Plastic hinge



BABTV  
Ball lock pins lockable  
, Stainless steel



CHAuss  
Screwed hinge, 270°



HCSS  
Set screw with  
hexagonal socket,  
Cup point



ACLEPP  
Right angled bracket  
for aluminium profile,  
4 holes



EMAS  
Antistatic knurled nut,  
Antistatic



GG1  
Ground spur gear,  
Heat treated steel



BLM  
Spring loaded plunger  
with ball tip, Plastic  
body



GMK17\_BROSSE  
Brush strip, Cone-  
shaped - brush



DBL820  
Idler for slat top  
chain, Ranges 820  
and 815

Complementary products