

Cable-carrier chain for aluminium profile

PRFCH **MiniTec** For profile PRF4545-G-3



- Supplied in metre lengths, this chain simply clips together
- 2 part fixing link required
- Material: black plastic

Uses

- For supporting and guiding cables/hoses on moveable structures such as trolleys


Assembly

- PRF4545-ACH links permit multiple chains to be joined to obtain the total length required
- Clip chains together to get the length desired

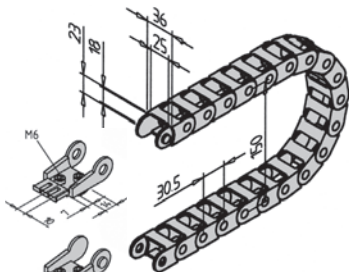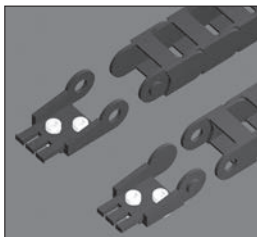

PRF4545-CH

PRF4545-ACH

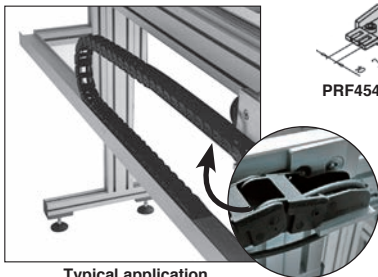

Typical application

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Type	Length (mm)	Weight (kg)	Price each 1 to 4
PRF4545-CH	Cable-carrier chain	1000	0,341	108,08 €
PRF4545-ACH	Link	-	0,058	24,01 €

Dimensions in mm


Our other products



DER63
Stainless steel AC asynchronous motor
0.18 kW, 0.18kW



 RFV40
Stainless steel worm and wheel gearbox,
up to 47 Nm



QNJ
Single row cylindrical roller bearing, Single
flange on inner ring



TCXR
Automatic chain tensioner, With steel
sprocket



RAS
90°ball and socket
joints DIN71802,
Stainless steel



RHTc55
High Temperature
Castor, up to 200kg



 
VTSM
Ball head screws
Hygienic Design®,
Stainless steel



NKX
Combined bearing
without inner ring,
Needle and ball
bearings



GGP
Male wing knob,
Technopolymer with
stainless steel spindle



PRF LIS
Door seal for
aluminium profile,
Black NBR



DB
Steel bevel gear, 2:1



CLSCLP_SS
Clevis components,
short version,
Stainless steel - short
range

Complementary products