

Hinge for aluminium profile



Stock

PRFCHA **MiniTec**


Framing hinge

- Face mounting hinges


- Designed to support large doors and panels
- Allows profiles to be joined at any angle
- For heavy doors/panels, use multiple hinges
- Supplied with protective covers but not the fixing kit
- Material: grey powder coated aluminium GD

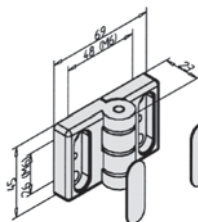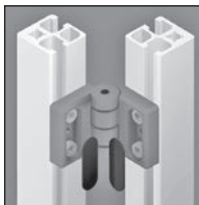


PRF19-CHA

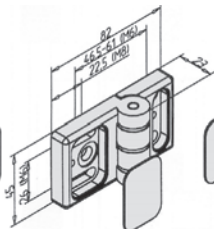

PRF32-CHA

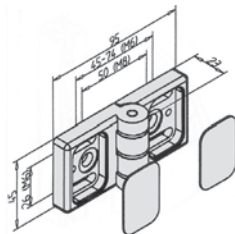

PRF45-CHA

 

Typical application

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	For profile	Load (N)	Weight (kg)	Stock*	Price each 1 to 49
PRF-19-CHA	PRF19, PRF32	600	0,090	✓	11,74 €
PRF-32-CHA	PRF19, PRF32, PRF45	600	0,095	✓	11,74 €
PRF-45-CHA	PRF45	600	0,104	✓	11,74 €

*Depending on availability - Dimensions in mm

Our other products



QNJ
Single row cylindrical roller bearing, Single flange on inner ring



GMK17_BR
Clamp for guiding profile, Rounded only - single



FF10
Offset spur gear reducer, from 0.78 to 3.70 Nm



SUPTOOL
Installation tools for clamping hub, For hexagonal clamping hub



YG1
HEAVY DUTY spur gear, Steel 35NCD6



PSG1
Spur gear - precision range, Pre-hardened Steel 35NCD6



SVG
Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...



BAGO
Locking rings in steel , Steel



MDR
Dee shackle with eye bolt, Steel



DIL
Lever operated locking bolt, lever



PM4
Worm and wheel set, Hardened steel



ACAsS
Stainless steel splined shaft, Stainless steel

Complementary products



PRF4545
Standard aluminium profile, 45 x 45 mm