

# Hinge for aluminium profile



Stock

PRFCHA **MiniTec**


Framing hinge

**- Face mounting hinges**


- Designed to support large doors and panels
- Allows profiles to be joined at any angle
- For heavy doors/panels, use multiple hinges
- Supplied with protective covers but not the fixing kit
- Material: grey powder coated aluminium GD

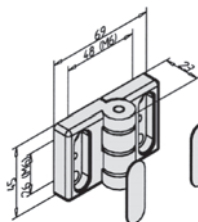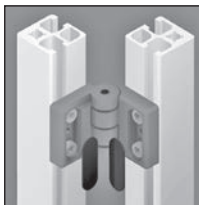



PRF19-CHA

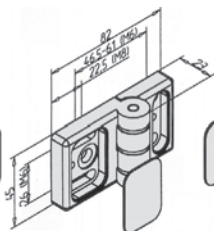

PRF32-CHA

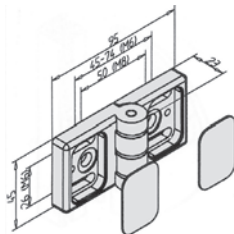

PRF45-CHA

  

Typical application

**DISCOUNTS**

Qty	1+	50+	100+
Disc. List	-5%	On request	

Part number	For profile	Load (N)	Weight (kg)	Stock*	Price each 1 to 49
PRF-19-CHA	PRF19, PRF32	600	0,090	✓	11,74 €
PRF-32-CHA	PRF19, PRF32, PRF45	600	0,095	✓	11,74 €
PRF-45-CHA	PRF45	600	0,104	✓	11,74 €

\*Depending on availability - Dimensions in mm

## Our other products




DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



MHX

 Hexagonal threaded sleeve, Hexagonal - steel



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



BSP

Compact precision slide, from 156 N to 980 N



PR40

Articulated foot Ø50, Ø 50



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls



PGMT

Pull handle, Stainless steel



EPE

Wing nuts Hygienic Design®, Narrow



SC2

2 part rigid shaft clamp, Clamping jaw



CABPVC

PVC covered galvanised steel cable, Galvanised



DB

Steel bevel gear, 2:1



RFK38C

Hypoid gearbox - Stainless steel, up to 200 Nm

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm