

# Cable clip

PRFCLIP **MiniTec**

For electrical cables  
and pneumatic tubing



- Material: grey PA6 polyamide

## Uses

- Simple fastening of electric and pneumatic cables

## Assembly

- Insert the clip into the profile and make a quarter turn to secure it in place
- Insert a suitably sized LAS cable tie, position the cable/tube and fully tighten the cable tie, removing the excess material

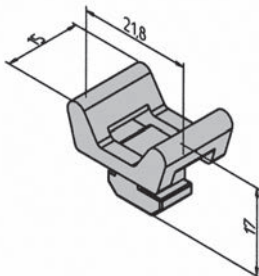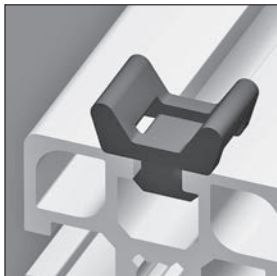

Typical application

## DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-CLIP-22	Cable clip	0,002	✓	1,36 €

\*Depending on availability - Dimensions in mm

## Our other products



RTE

Rotex®, jaw coupling,  
Aluminium



MC

Self-compensating  
shock-absorber, Self-  
compensating -  
without adjust...



 
VAB

Flanged nut for ball  
screw, For VAB  
ballscrew



RAS

90° ball and socket  
joints DIN71802,  
Stainless steel



AWMP

Aluminium shaft for  
linear guide,  
Aluminium



VTHbr

Hexagonal headed  
screw VTH - DIN933,  
Brass



SLV

Vertical toggle clamp,  
Vertical Lever Clamp -  
steel



HS

Hexagonal spacer,  
Stainless steel 303



GP75

Spring loaded toggle  
latch, Standard



BLHT50

Right angled gearbox,  
from 11.50 to 30 Nm



BTC

End cap for square  
tube, Standard



TB8

Cylindrical roller  
thrust bearing, Steel

## Complementary products



PRF4545

Standard aluminium  
profile, 45 x 45 mm