



- Square nut with sprung tab
- Nut can be inserted at any point along the slot in a profile
- Material: zinc plated or stainless steel
- Not sold individually, contact us for details

steel or stainless steel




Advantages

- Allows parts to be added/removed easily
- Sprung tabs allows the nut to be retained in place when using vertically positioned profiles

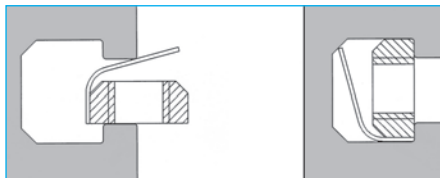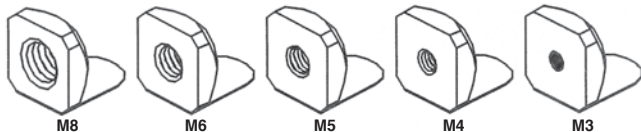

Very simple positioning

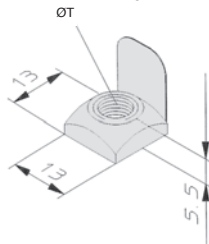

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number		ØT	Stock* Steel	Price each 1 to 49	
Steel	Stainless steel			Steel	Stainless steel
PRF-ECL-M3	PRF-ECL-M3/SS	M3	✓	0,78 €	2,40 €
PRF-ECL-M4	PRF-ECL-M4/SS	M4	✓	0,78 €	2,40 €
PRF-ECL-M5	PRF-ECL-M5/SS	M5	✓	0,78 €	2,40 €
PRF-ECL-M6	PRF-ECL-M6/SS	M6	✓	0,78 €	2,40 €
PRF-ECL-M8	PRF-ECL-M8/SS	M8	✓	0,78 €	2,40 €

*Depending on availability - Dimensions in mm

Our other products



PR105
Articulated foot Ø103,
Ø 103



PRF_RR
Coupling bar for
aluminium profile,
Coupling bar



PSG25
Spur gear - precision
range, Pre-hardened
Steel 35NCD6



RPB
Ball screw bearing
unit, Support



HLUss
Spoked handwheel,
Stainless steel 316



CLASS
Stainless steel
indexing handle -
female, Stainless steel



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



DOMI120
Connecting kits, XZ
linking kit



AT10-32ECO
AT type timing pulley,
Economy range -



SHSS
Shoulder screw
stainless steel 416,



MRASSeco
Low cost stainless
steel quick link,



SSDB
Stainless steel bevel
gear, 2:1

Complementary products




PRF4545
Standard aluminium
profile, 45 x 45 mm



PRF_FIX_ANG
Fastener for
aluminium profile,
Angular joint



 ACL-PR
Joining plate for
aluminium profile,
Right angled
connection



ACL-PR
Joining plate for
aluminium profile,
Right angled
connection