



- Square nut with sprung tab
- Nut can be inserted at any point along the slot in a profile
- Material: zinc plated or stainless steel
- Not sold individually, contact us for details

steel or stainless steel




### Advantages

- Allows parts to be added/removed easily
- Sprung tabs allows the nut to be retained in place when using vertically positioned profiles

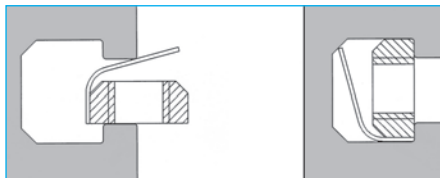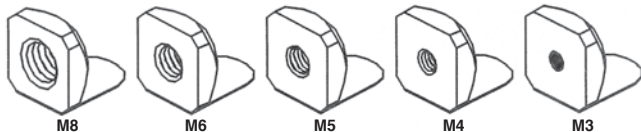

Very simple positioning

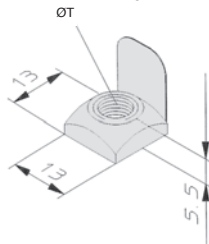

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number		ØT	Stock* Steel	Price each 1 to 49	
Steel	Stainless steel			Steel	Stainless steel
PRF-ECL-M3	PRF-ECL-M3/SS	M3	✓	0,78 €	2,40 €
PRF-ECL-M4	PRF-ECL-M4/SS	M4	✓	0,78 €	2,40 €
PRF-ECL-M5	PRF-ECL-M5/SS	M5	✓	0,78 €	2,40 €
PRF-ECL-M6	PRF-ECL-M6/SS	M6	✓	0,78 €	2,40 €
PRF-ECL-M8	PRF-ECL-M8/SS	M8	✓	0,78 €	2,40 €

\*Depending on availability - Dimensions in mm

## Our other products



**BAB5303**  
303 Stainless steel  
compact ball pin,  
Stainless steel 303



**WFRM**  
Flanged polymer nut,  
Polymer (Iglidur®) - 1  
thread



**MBEX**  
Hexagonal ended  
handle, Hexagonal  
ended handle



**SSB**  
Stainless steel bevel  
gear, 1:1



**VRM**  
Female swivelling  
lifting rings, Female  
swivelling



**VCMB**  
Dual-thread screw  
wood/metal, Steel



**G0**  
Steel spur gear, Steel  
20NCD2



**NK40**  
Drylin®N miniature  
guiding system, Withd  
40 mm



**FF15**  
Offset spur gear  
reducer, from 2.20 to  
10 Nm



**T25-6ECO**  
T type timing pulley,  
Economy range - T2.5  
aluminium



**TMR**  
Rigid manual  
tensioner, Adjustable



**T5-16ECO**  
T type timing pulley,  
Economy range - T5  
aluminium


## Complementary products



**PRF4545**  
Standard aluminium  
profile, 45 x 45 mm



 **PRF\_FIX\_ANG**  
Fastener for  
aluminium profile,  
Angular joint



**PRF4545r90**  
Standard aluminium  
profile, 45 x 45 mm -  
R90°



**PRF-SCL**  
Lock for aluminium  
profile, Lock for  
sliding doors