



- Square nut with sprung tab
- Nut can be inserted at any point along the slot in a profile
- Material: zinc plated or stainless steel
- Not sold individually, contact us for details

steel or stainless steel




### Advantages

- Allows parts to be added/removed easily
- Sprung tabs allows the nut to be retained in place when using vertically positioned profiles

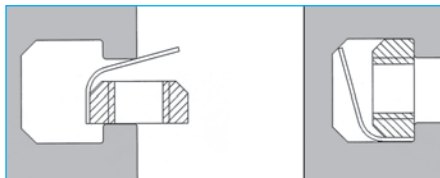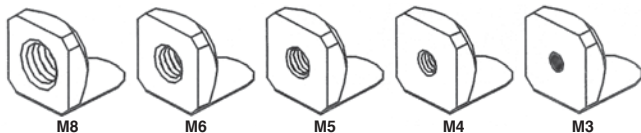

Very simple positioning

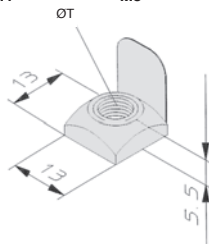

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%	On request	

Part number		ØT	Stock* Steel	Price each 1 to 49	
Steel	Stainless steel			Steel	Stainless steel
PRF-ECL-M3	PRF-ECL-M3/SS	M3	✓	0,78 €	2,40 €
PRF-ECL-M4	PRF-ECL-M4/SS	M4	✓	0,78 €	2,40 €
PRF-ECL-M5	PRF-ECL-M5/SS	M5	✓	0,78 €	2,40 €
PRF-ECL-M6	PRF-ECL-M6/SS	M6	✓	0,78 €	2,40 €
PRF-ECL-M8	PRF-ECL-M8/SS	M8	✓	0,78 €	2,40 €

 
\*Depending on availability - Dimensions in mm

## Our other products



PRT-TO

iglidur® slewing ring,  
With external teeth-  
Iglidur®, aluminium &  
S...



PX\_PO

Carrying handle,  
standard



DB

Steel bevel gear, 2:1



SVT15

Screwjack with  
travelling screw, with  
translating screw



CHMR90

Worm and wheel gear  
reducer, up to 540  
Nm



AC

Strike for toggle latch,  
13mm



 
BVR

Adjustable screw stop,  
Steel



LRR-53

Spring loaded latch,  
Spring return latch -  
steel



PM3

Worm and wheel set,  
Machined plastic  
(delrin)



BOX-NINA

Self locking nut -  
DIN985, Box set of  
steel nuts



PF40

Worm and wheel gear  
reducer, up to 18 Nm



KBS\_UU

Stainless steel closed  
precision linear  
bearing, Precision -  
stainle...

## Complementary products




PRF4545

Standard aluminium  
profile, 45 x 45 mm



PRF\_FIX\_ANG

 Fastener for  
aluminium profile,  
Angular joint



PRF4545r90

Standard aluminium  
profile, 45 x 45 mm -  
R90°



PRF-SCL

Lock for aluminium  
profile, Lock for  
sliding doors