

# Fastener for aluminium profile



**PRF  
FIXANG**


**MiniTec**

**Angular joint**




- Creates an angular joint between the end of a profile and the side of a second.
- Fixing kit supplied
- Material: electroplated steel

## Assembly

- Drill a  $\varnothing 10.2\text{mm}$  in the centre of the side of the horizontal profile
- Drill a  $\varnothing 8.2\text{ mm}$  at a distance A (see table) from the end of the angled profile
- Insert the angled fastener in the  $\varnothing 10.2\text{mm}$  hole
- Position the PRF-ECL-M8 nut in the slot at  $\varnothing 8.2$  hole
- Tighten the joint by means of the M8 grubscrew

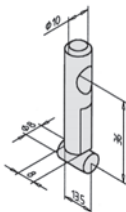

a	25°	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°	80°	85°
A(mm)	21	24	26	28	29	30	30,5	31	31,5	32	32	32	32

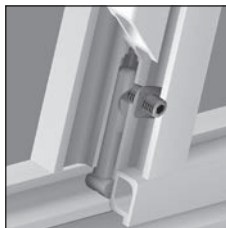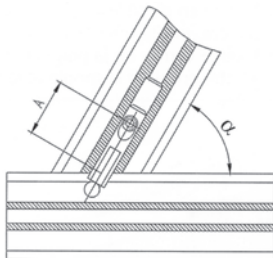 

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-ANG	0,051	✓	11,74 €

\*Depending on availability - Dimensions in mm


## Our other products



PF60  
Worm and wheel gear reducer, up to 118 Nm



PTA40  
Articulated foot with solid base foot Ø 40, 3000N

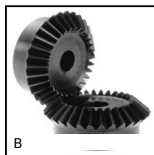


B  
Steel bevel gear, 1:1



RPCpl  
Swivel castor with plate, Steel - Polyamide



OP2  
Mechanical digital position indicator, 3 numbers

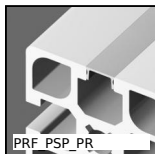

PRF\_PSP\_PR  
Dual purpose strip and cover for aluminium profile, Inserts into slot



PTAF100-PAMF100  
Articulated fixable foot with pressed base Ø100, Ø 100



PO  
Pull handle - Multi-sector, Tapped recessed insert




R\_RR  
Narrow spur rack, Steel



AXTR  
Axle for tensioner pulley, Shaft



EHD08-3  
Internal epicyclic servo reducers, from 5000 Nm

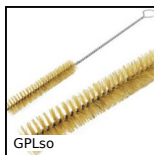

GPLso  
Brush, silk

## Complementary products



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab



PRF4545  
Standard stainless steel profile, 45 x 45 mm



PRF\_FIX\_UNI  
Universal fastener for aluminium profile, Universal