

# Fastener for aluminium profile

Stock

PRF **MiniTec**  
FIXANG


Angular joint

- Creates an angular joint between the end of a profile and the side of a second.
- Fixing kit supplied
- Material: electroplated steel






## Assembly

- Drill a  $\varnothing 10.2\text{mm}$  in the centre of the side of the horizontal profile
- Drill a  $\varnothing 8.2\text{ mm}$  at a distance A (see table) from the end of the angled profile
- Insert the angled fastener in the  $\varnothing 10.2\text{mm}$  hole
- Position the PRF-ECL-M8 nut in the slot at  $\varnothing 8.2$  hole
- Tighten the joint by means of the M8 grubscrew

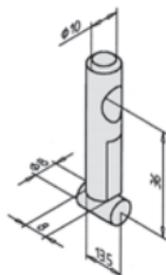

a	25°	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°	80°	85°
A(mm)	21	24	26	28	29	30	30,5	31	31,5	32	32	32	32

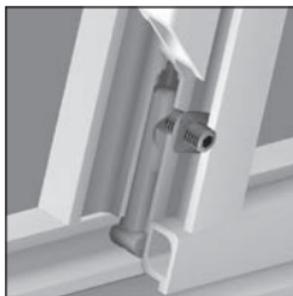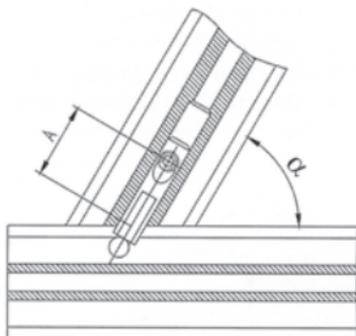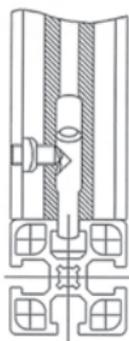

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-ANG	0,051	✓	11,74 €

\*Depending on availability - Dimensions in mm

## Our other products



UGH32

H Type Guide units,  
For Ø32 actuators



CHB

Single output shaft,  
For CHB gearbox



J51

Spur gear coaxial  
gearbox, from 0.13 to  
0.49 Nm - Inline



MHWC

Double-disc flexible  
coupling, Double disk



BCM\_CC

Modular cylindrical  
brush, Horsehair  
bristles



AT10-32ECO

AT type timing pulley,  
Economy range -  
AT10 aluminium



MLY

Bow shackle with eye  
bolt, Steel



ZBconique

Machined plastic  
bevel gear, 1:1



PHTss

Pull handle, Up to 250  
°C



CHM75

Worm and wheel gear  
reducer, up to 298



EHD04

Internal epicyclic  
servo reducers, from



ESCON

Speed controller 5A, 5  
A

## Complementary products



PRF\_ECL

Nut for aluminium  
profile, Steel square  
nut with tab



PRF4545

Standard stainless  
steel profile, 45 x 45  
mm



PRF\_FIX\_UNI

Universal fastener for  
aluminium profile,  
Universal