

# Fastener for aluminium profile

Stock

PRF **MiniTec**  
FIXANG


Angular joint

- Creates an angular joint between the end of a profile and the side of a second.
- Fixing kit supplied
- Material: electroplated steel






## Assembly

- Drill a  $\varnothing 10.2\text{mm}$  in the centre of the side of the horizontal profile
- Drill a  $\varnothing 8.2\text{ mm}$  at a distance A (see table) from the end of the angled profile
- Insert the angled fastener in the  $\varnothing 10.2\text{mm}$  hole
- Position the PRF-ECL-M8 nut in the slot at  $\varnothing 8.2$  hole
- Tighten the joint by means of the M8 grubscrew

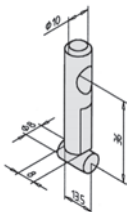

a	25°	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°	80°	85°
A(mm)	21	24	26	28	29	30	30,5	31	31,5	32	32	32	32

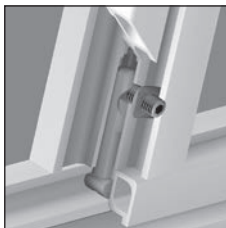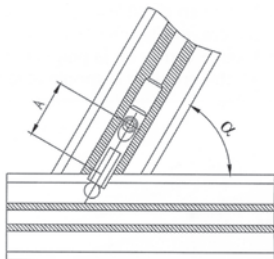 

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-ANG	0,051	✓	11,74 €


\*Depending on availability - Dimensions in mm

## Our other products



T5-BAR

T type tooth bar  
stock, T5

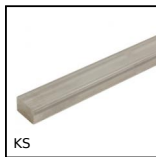

KS

Keysteel, Stainless  
steel - Keystock



BLOC

Doorstop, Doorstop




PC5505S

Chain sprocket -  
Stainless steel,  
12.7mm (DIN 08B-1)



G1

Steel spur gear, Steel  
20NCD2

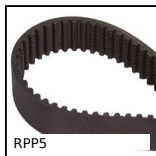

RPP5

RPP heavy duty  
timing belt, RPP5



GLB

Small 6 lobe threaded  
handle - female,  
Technopolymer -  
Stainless steel



BLM

Spring loaded plunger  
with ball tip, Stainless  
steel body



AT5M AT10M

AT type timing belt  
per metre, AT10 Steel  
cored polyurethane



D-PAR\_SS

Stainless steel  
progressive stop,  
stainless steel



PRF\_PL\_4590

Joining plate for  
aluminium profile,  
Joint plate - 45x90



CHM110

Worm and wheel gear  
reducer, up to 980  
Nm

## Complementary products



PRF\_ECL

Nut for aluminium  
profile, Steel square  
nut with tab



PRF4545

Standard stainless  
steel profile, 45 x 45  
mm



PRF\_FIX\_UNI

Universal fastener for  
aluminium profile,  
Universal