

# Fastener for aluminium profile

Stock

PRF **MiniTec**  
FIXANG


Angular joint

- Creates an angular joint between the end of a profile and the side of a second.
- Fixing kit supplied
- Material: electroplated steel






## Assembly

- Drill a  $\varnothing 10.2\text{mm}$  in the centre of the side of the horizontal profile
- Drill a  $\varnothing 8.2\text{ mm}$  at a distance A (see table) from the end of the angled profile
- Insert the angled fastener in the  $\varnothing 10.2\text{mm}$  hole
- Position the PRF-ECL-M8 nut in the slot at  $\varnothing 8.2$  hole
- Tighten the joint by means of the M8 grubscrew

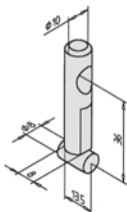

a	25°	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°	80°	85°
A(mm)	21	24	26	28	29	30	30,5	31	31,5	32	32	32	32

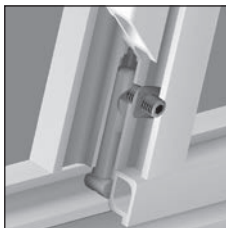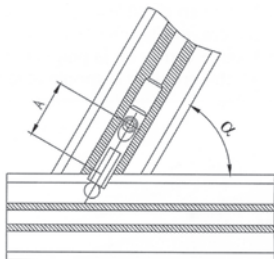 

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-ANG	0,051	✓	11,74 €

\*Depending on availability - Dimensions in mm

## Our other products




MAX22  
Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



PO  
Pull handle - Multi-sector, Smooth hole



 
BFA  
Shaft locking washer, E clip



RPPM  
RPP type belt per metre, RPP5 Steel cored polyurethane



 EPE  
Wing nuts Hygienic Design®, Narrow



PRFbou  
Emergency release button for aluminium profile, Emergency release bu...



PTA40  
Articulated foot with solid base foot Ø 40, 30000N



S\_ZZ  
Deep groove ball bearing, Stainless steel



MEB  
Moulded plastic bevel gear (nylon), 1:1



BUH77  
Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



SH3  
Parallel axis helical gear, Machined plastic (delrin)



VPRA\_M  
Handwheel with handle, Thermosetting plastic - stainless steel hub

## Complementary products



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab



PRF4545  
Standard stainless steel profile, 45 x 45 mm



PRF\_FIX\_UNI  
Universal fastener for aluminium profile, Universal