

# Lip seal for panel

PRFJL **MiniTec** For 2mm thick panels

- Material: black EPDM
- Seal sold by the metre

## Uses



- For supporting and sealing 2mm thick panels in profile slots
- Should not be used with acrylic or polycarbonate panels

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool
- For panels thinner than 2mm, use 2 PRF-JL-6 seals on either side of the panel instead.

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

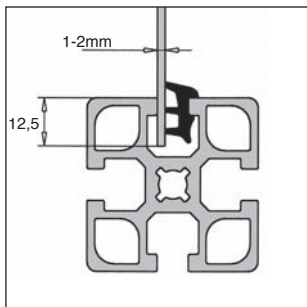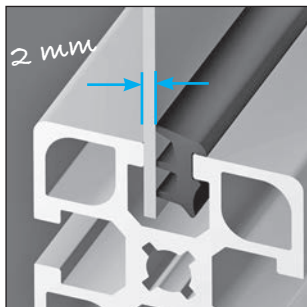

Assembly example

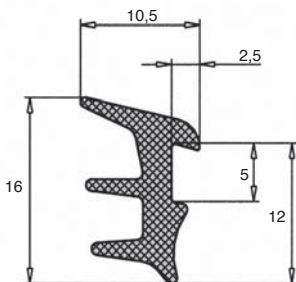

## DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-2	Lip seal	0,092	3,40 €

 
Dimensions in mm

## Our other products



BPQ

Quadro linear ball bearing unit, Included 4 linear ball bearings



CRM

Moulded nylon rack, Nylon




WJUM20

Drylin® W bearing block, Slide



PPRss

 Pad eye on mounting plate round, Stainless steel



M1

Worm and wheel set, Bronze



BEAS

Star shaped anti-static handle, Star, anti-static



BAGtr

Lead screw clamping collar, Aluminium



PW\_PWG15

Worm - precision range, Stainless steel



CHMR110

Worm and wheel gear reducer, up to 980 Nm



VTLF

3 lobed handle, Polyamide - Brass



MCLred

Reducing sleeve female/female, Cylindrical - steel



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter

## Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm